

# Home - Fischerelektronik - LA 15



 [fischerelektronik.de/web\\_fischer/en\\_GB/VA/LA1540024/datasheet.xhtml](http://fischerelektronik.de/web_fischer/en_GB/VA/LA1540024/datasheet.xhtml)



## Features

|                                     |                                                                              |
|-------------------------------------|------------------------------------------------------------------------------|
| width:                              | 240 mm                                                                       |
| height:                             | 120 mm                                                                       |
| length:                             | 400 mm                                                                       |
| thermal resistance:                 | 0.083 - 0.032 K/W                                                            |
| surface:                            | raw degreased aluminium (by the metre raw aluminium)                         |
| operating voltage of the fan motor: | <ul style="list-style-type: none"><li>• 24 V DC</li><li>• 230 V AC</li></ul> |

## Technical Drawing

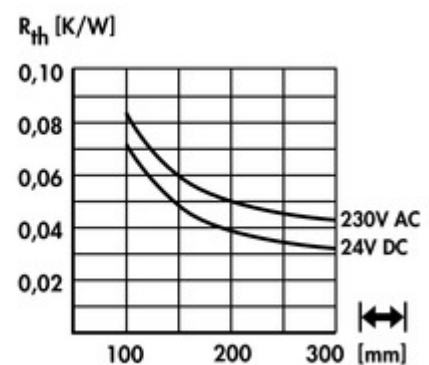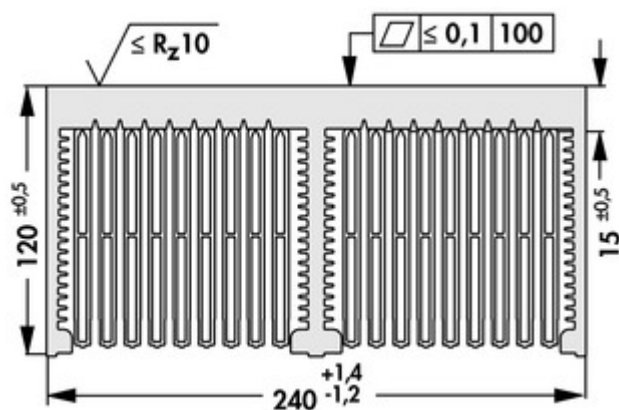

## Fan

type: ebmpapst 4184NXH

|                                  |                                   |
|----------------------------------|-----------------------------------|
| dimensions:                      | 119x119x38 mm                     |
| tension:                         | 24 V DC                           |
| power inout:                     | 11 W                              |
| max. air volume:                 | 237 m <sup>3</sup> /h             |
| temperature range:               | -30°C ... +70°C                   |
| speed:                           | 4,400 min <sup>-1</sup>           |
| noise level:                     | 57 dB(A)                          |
| weight:                          | 390 g                             |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 70,000 h (40°C) |
| type:                            | ebmpapst 4656N                    |
| dimensions:                      | 119x119x38 mm                     |
| tension:                         | 230 V AC                          |
| power inout:                     | 19 W                              |
| max. air volume:                 | 160 m <sup>3</sup> /h             |
| temperature range:               | -40°C... +85°C                    |
| speed:                           | 2,650 min <sup>-1</sup>           |
| noise level:                     | 47 dB(A)                          |
| weight:                          | 550 g                             |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 37,500 h (40°C) |

