

Home - Fischerelektronik - LA 17



fischerelektronik.de/web_fischer/en_GB/VA/LA1740024/datasheet.xhtml



Features

width:	122 mm
height:	120 mm
length:	400 mm
thermal resistance:	0.103 - 0.053 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 24 V DC • 230 V AC

Technical Drawing

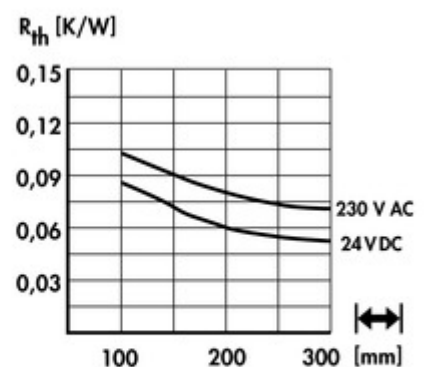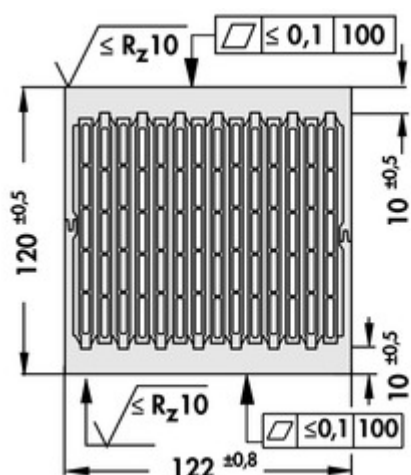

Fan

type:	ebmpapst 4184NXH
dimensions:	119x119x38 mm
tension:	24 V DC
power inout:	11 W
max. air volume:	237 m ³ /h
temperature range:	-30°C ... +70°C
speed:	4,400 min ⁻¹
noise level:	57 dB(A)
weight:	390 g
failure rate (L ₁₀):	L ₁₀ > 70,000 h (40°C)

type:	ebmpapst 4656N
dimensions:	119x119x38 mm
tension:	230 V AC
power inout:	19 W
max. air volume:	160 m ³ /h
temperature range:	-40°C... +85°C
speed:	2,650 min ⁻¹
noise level:	47 dB(A)
weight:	550 g

failure rate (L_{10}): $L_{10} > 37,500 \text{ h (40°C)}$

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de