

Home - Fischerelektronik - LA 20

fischerelektronik.de/web_fischer/en_GB/VA/LA20200/datasheet.xhtml

Features

width: 300 mm

height: 126 mm


length: 200 mm

thermal resistance: 0.032 - 0.014 K/W

surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

Technical Drawing

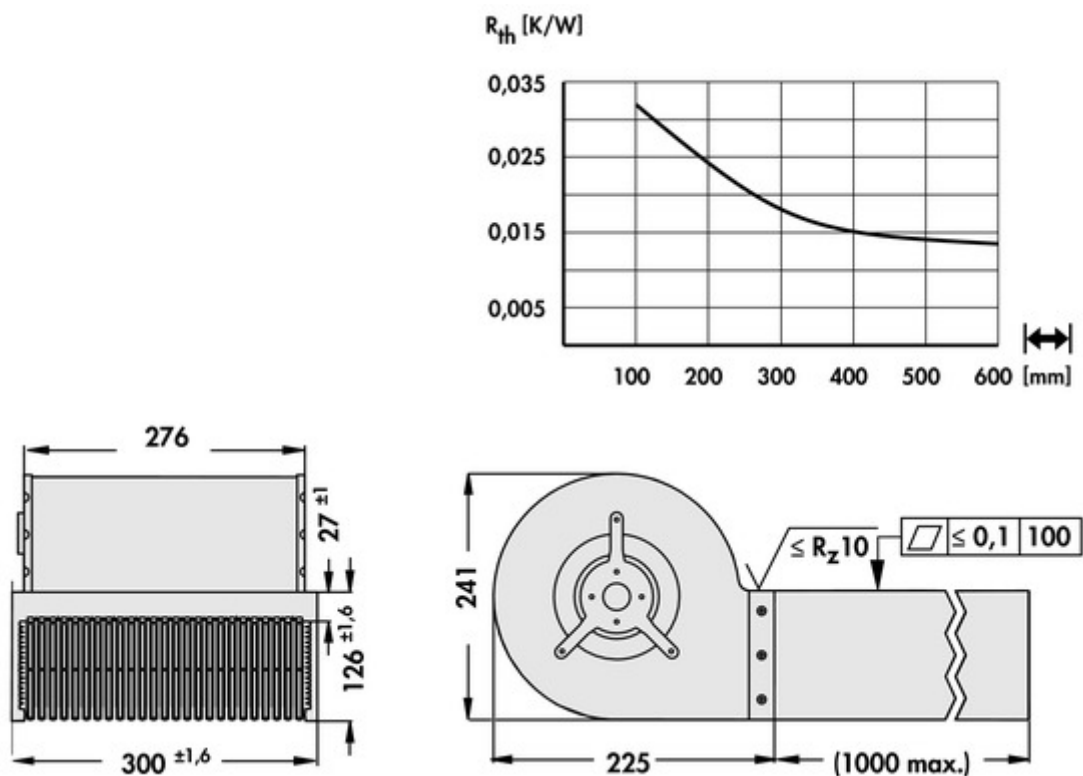

Fan

bearing type:	ball bearing
type:	ebmpapst, radial blower with grid, double sided absorbtion
discharge air flow:	1,310 m ³ /h
rotation speed:	1,350 min ⁻¹
power inout:	185 W
current consumption:	0.81 A
circuit voltage:	230 V AC
temperature range:	-25°C... +70°C
motor condenser:	6 µF
noise level:	64 dB(A)
weight:	5900 g