

Home - Fischerelektronik - LA 20

fischerelektronik.de/web_fischer/en_GB/VA/LA20300/datasheet.xhtml

Features

width: 300 mm

height: 126 mm


length: 300 mm

thermal resistance: 0.032 - 0.014 K/W

surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

Technical Drawing

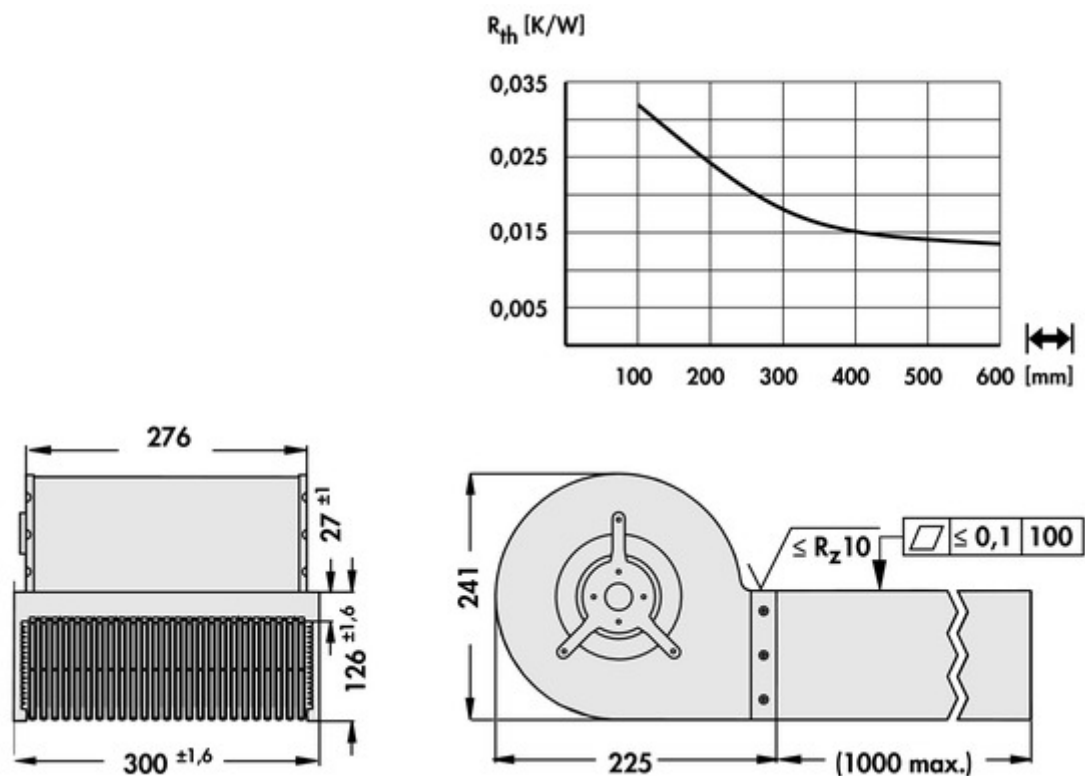

Fan

bearing type: ball bearing

type: ebmpapst, radial blower with grid, double sided absorbtion

discharge air flow: 1,310 m³/h

rotation speed: 1,350 min⁻¹

power inout: 185 W

current consumption: 0.81 A

circuit voltage: 230 V AC

temperature range: -25°C... +70°C

motor condenser: 6 µF

noise level: 64 dB(A)

weight: 5900 g

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de