

Home - Fischerelektronik - LA 21

 fischerelektronik.de/web_fischer/en_GB/VA/LA21200230/datasheet.xhtml

Features

width: 92 mm

height: 93 mm

length: 200 mm

thermal resistance: 0.19 - 0.078 K/W



surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor:

- 24 V DC
- 230 V AC

Technical Drawing

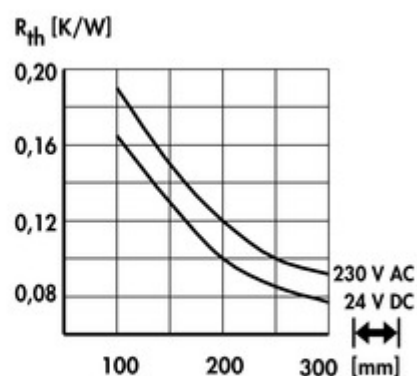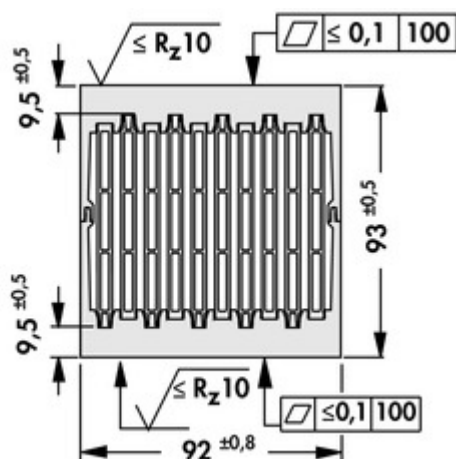

Fan

type: ebmpapst 3314 NHH

dimensions:	92x92x32 mm
tension:	24 V DC
power inout:	3.4 W
max. air volume:	107 m ³ /h
temperature range:	-20°C... 75°C
speed:	3,450 min ⁻¹
noise level:	42 dB(A)
weight:	190 g
failure rate (L ₁₀):	L ₁₀ > 57,500 h (40°C)
type:	ebmpapst 3656
dimensions:	92x92x38 mm
tension:	230 V AC
power inout:	12 W
max. air volume:	75 m ³ /h
temperature range:	-40°C... +75°C
speed:	2,700 min ⁻¹
noise level:	37 dB(A)
weight:	420 g
failure rate (L ₁₀):	L ₁₀ > 52,500 h (40°C)

