

Home - Fischerelektronik - LA 25

fischerelektronik.de/web_fischer/en_GB/VA/LA25300230/datasheet.xhtml

Features

width: 160 mm

height: 165 mm


length: 300 mm

thermal resistance: 0.095 - 0.049 K/W

surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

Technical Drawing

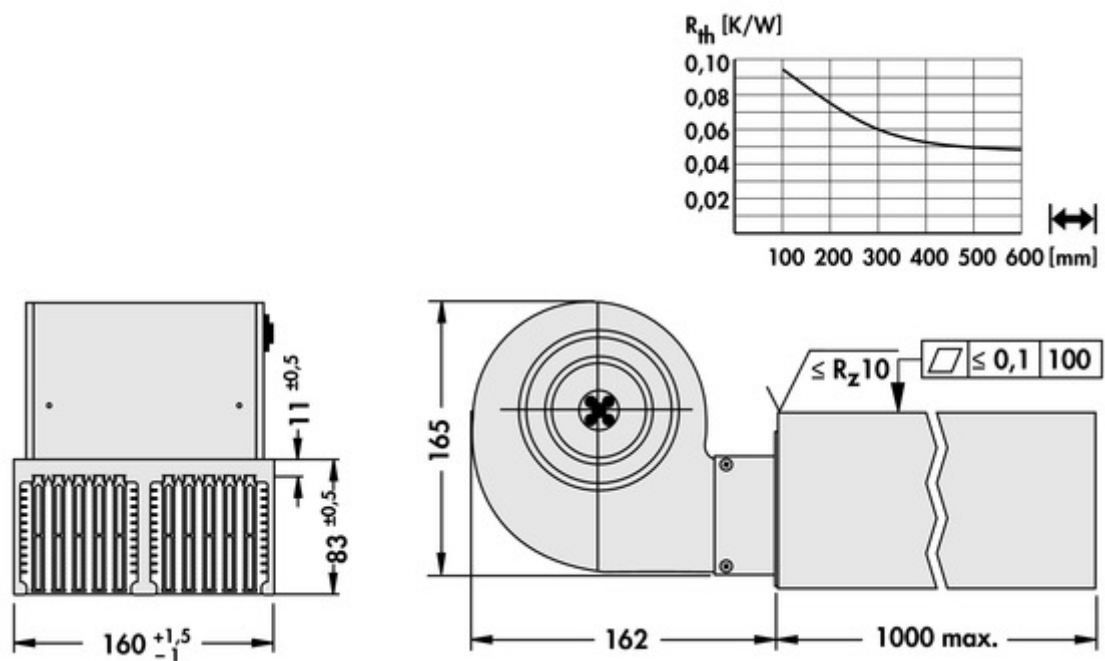

Fan

bearing type:	ball bearing
type:	ebmpapst, radial blower with grid, double sided absorbtion
discharge air flow:	435 m ³ /h
rotation speed:	1,950 min ⁻¹
power inout:	87 W
current consumption:	0.39 A
circuit voltage:	230 V AC
temperature range:	-25°C... +40°C
motor condenser:	2 µF/400 V
noise level:	58 dB(A)
weight:	1500 g