

Home - Fischerelektronik - LA 22



fischerelektronik.de/web_fischer/en_GB/VA/LA2215024/datasheet.xhtml



Features

width:	184 mm
height:	93 mm
length:	150 mm
thermal resistance:	0.098 - 0.048 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 24 V DC • 230 V AC

Technical Drawing

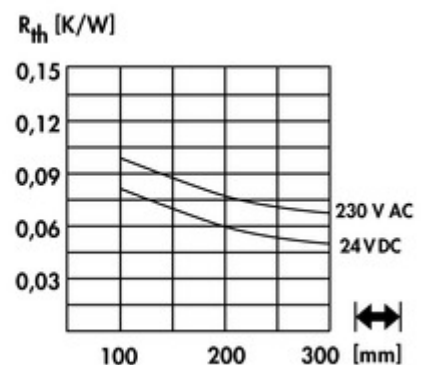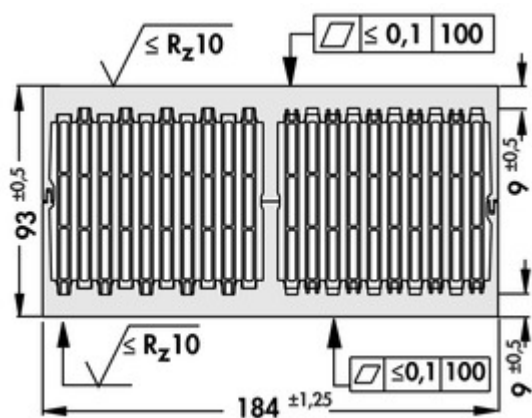

Fan

type:	ebmpapst 3314 NHH

dimensions:	92x92x32 mm
tension:	24 V DC
power inout:	3.4 W
max. air volume:	107 m ³ /h
temperature range:	-20°C... 75°C
speed:	3,450 min ⁻¹
noise level:	42 dB(A)
weight:	190 g
failure rate (L ₁₀):	L ₁₀ > 57,500 h (40°C)
type:	ebmpapst 3656
dimensions:	92x92x38 mm
tension:	230 V AC
power inout:	12 W
max. air volume:	75 m ³ /h
temperature range:	-40°C... +75°C
speed:	2,700 min ⁻¹
noise level:	37 dB(A)
weight:	420 g
failure rate (L ₁₀):	L ₁₀ > 52,500 h (40°C)

