

Home - Fischerelektronik - LA 27 K



fischerelektronik.de/web_fischer/en_GB/VA/LA27K8424/datasheet.xhtml



Features

width:	75.5 mm
height:	65.8 mm
length:	84 mm
thermal resistance:	1.9 - 1.08 K/W
surface:	natural colour anodised
operating voltage of the fan motor:	• 12 V DC • 24 V DC

Technical Drawing

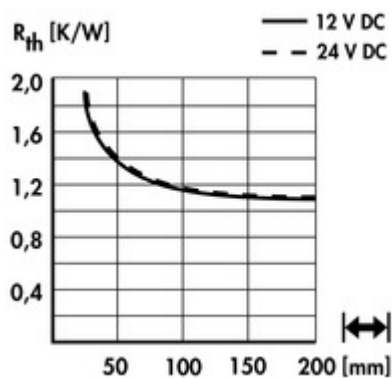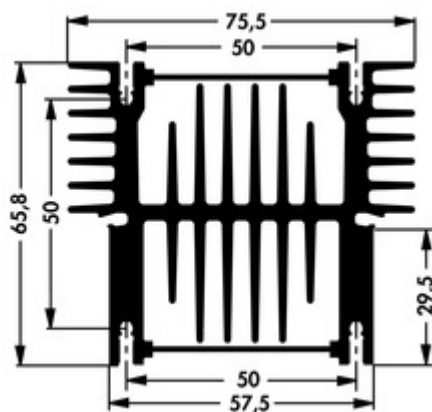

Fan

type: ebmpapst 612 NHH-118

dimensions:	60x60x25 mm
tension:	12 V DC
power inout:	2.9 W
max. air volume:	56 m ³ /h
temperature range:	-20°C... +70°C
speed:	6,800 min ⁻¹
noise level:	41 dB(A)
weight:	66 g
failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)
type:	ebmpapst 614 NHH-119
dimensions:	60x60x25 mm
tension:	24 V DC
power inout:	2.9 W
max. air volume:	56 m ³ /h
temperature range:	-20°C... +70°C
speed:	6,850 min ⁻¹
noise level:	41 dB(A)
weight:	66 g
failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)

