



Home - Fischerelektronik - LA 32

 fischerelektronik.de/web_fischer/en_GB/VA/LA3230012/datasheet.xhtml

Features

width:	164.6 mm
height:	85 mm
length:	300 mm
thermal resistance:	0.041 - 0.093 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 12 V DC • 24 V DC • 48 V DC

Technical Drawing

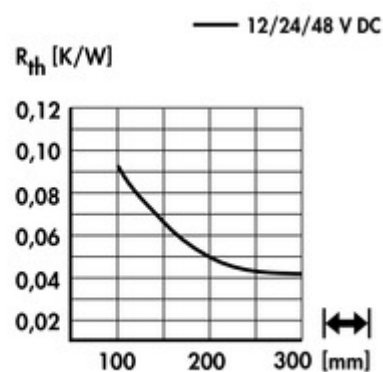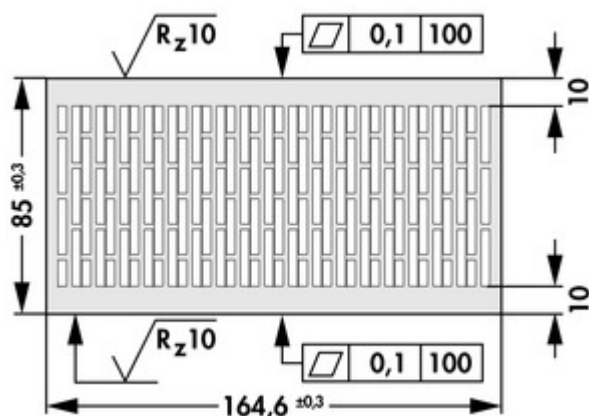

Fan

type:	ebmpapst 8212 JH4
dimensions:	80x80x38 mm

tension:	12 V DC
power inout:	39 W
max. air volume:	222 m ³ /h
temperature range:	-20°C... +70°C
speed:	14,000 min ⁻¹
noise level:	71 dB(A)
weight:	200 g
failure rate (L ₁₀):	L ₁₀ > 50,000 h (40°C)
type:	ebmpapst 8214 JH4
dimensions:	80x80x38 mm
tension:	24 V DC
power inout:	38 W
max. air volume:	222 m ³ /h
temperature range:	-20°C... +70°C
speed:	14,000 min ⁻¹
noise level:	71 dB(A)
weight:	200 g
failure rate (L ₁₀):	L ₁₀ > 50,000 h (40°C)
type:	ebmpapst 8218 JH4

dimensions:	80x80x38 mm
tension:	48 V DC
power inout:	36 W
max. air volume:	222 m ³ /h
temperature range:	-20°C... +70°C
speed:	14,000 min ⁻¹
noise level:	71 dB(A)
weight:	200 g
failure rate (L ₁₀):	L ₁₀ > 50,000 h (40°C)

Fischer Elektronik GmbH & Co. KG
 DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
 58511 Lüdenscheid

Telefon +49 2351 435-0
 Telefax +49 2351 45754

info@fischerelektronik.de
 www.fischerelektronik.de