

# Home - Fischerelektronik - LA 34

 [fischerelektronik.de/web\\_fischer/en\\_GB/VA/LA3415012/datasheet.xhtml](http://fischerelektronik.de/web_fischer/en_GB/VA/LA3415012/datasheet.xhtml)

## Features

width: 80 mm

height: 83 mm



length: 150 mm

thermal resistance: 0.2 - 0.117 K/W

surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

## Technical Drawing

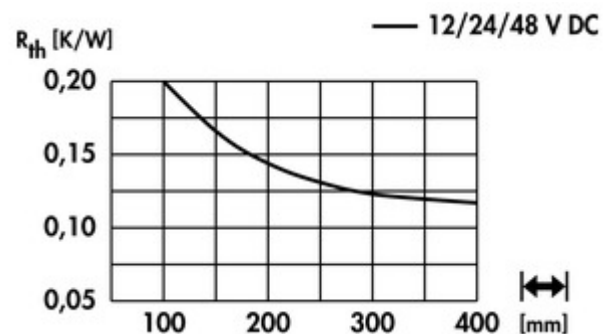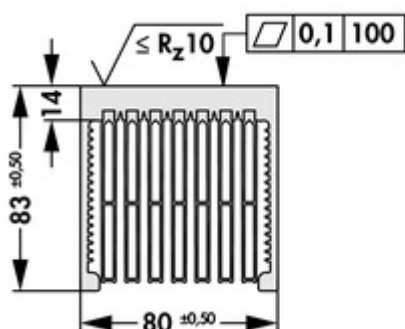

## Fan

type: ebmpapst 8212 JH4

dimensions: 80x80x38 mm

tension: 12 V DC

power inout: 39 W

|                                  |                                   |
|----------------------------------|-----------------------------------|
| max. air volume:                 | 222 m <sup>3</sup> /h             |
| temperature range:               | -20°C... +70°C                    |
| speed:                           | 14,000 min <sup>-1</sup>          |
| noise level:                     | 71 dB(A)                          |
| weight:                          | 200 g                             |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 50,000 h (40°C) |
| type:                            | ebmpapst 8218 JH4                 |
| dimensions:                      | 80x80x38 mm                       |
| tension:                         | 48 V DC                           |
| power inout:                     | 36 W                              |
| max. air volume:                 | 222 m <sup>3</sup> /h             |
| temperature range:               | -20°C... +70°C                    |
| speed:                           | 14,000 min <sup>-1</sup>          |
| noise level:                     | 71 dB(A)                          |
| weight:                          | 200 g                             |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 50,000 h (40°C) |
| type:                            | ebmpapst 8214 JH4                 |
| dimensions:                      | 80x80x38 mm                       |
| tension:                         | 24 V DC                           |

|                                  |                                   |
|----------------------------------|-----------------------------------|
| power inout:                     | 38 W                              |
| max. air volume:                 | 222 m <sup>3</sup> /h             |
| temperature range:               | -20°C... +70°C                    |
| speed:                           | 14,000 min <sup>-1</sup>          |
| noise level:                     | 71 dB(A)                          |
| weight:                          | 200 g                             |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 50,000 h (40°C) |

**Fischer Elektronik GmbH & Co. KG**  
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28  
58511 Lüdenscheid

Telefon +49 2351 435-0  
Telefax +49 2351 45754

info@fischerelektronik.de  
www.fischerelektronik.de