

Home - Fischerelektronik - LA 6

 fischerelektronik.de/web_fischer/en_GB/VA/LA620024/datasheet.xhtml

Features

width: 62 mm

height: 74 mm

length: 200 mm

thermal resistance: 0.2 - 0.1 K/W


surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor:

- 12 V DC
- 24 V DC

Technical Drawing

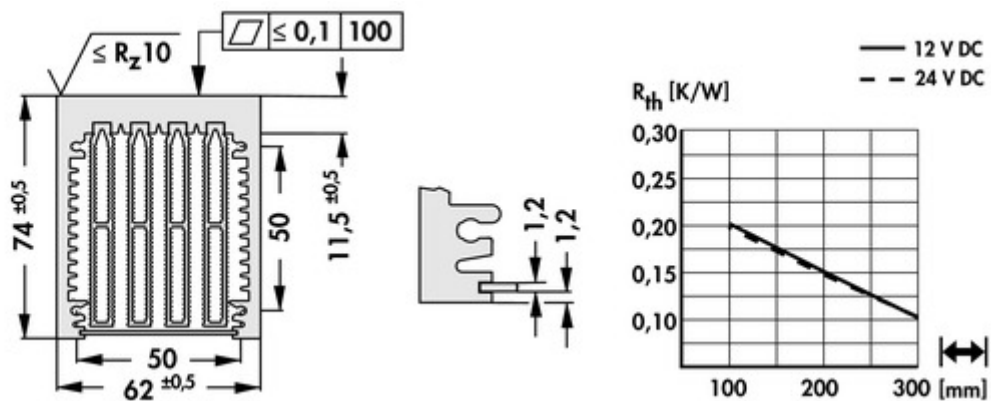

Fan

type: ebmpapst 612 NHH-118

dimensions: 60x60x25 mm

tension:	12 V DC
power inout:	2.9 W
max. air volume:	56 m ³ /h
temperature range:	-20°C... +70°C
speed:	6,800 min ⁻¹
noise level:	41 dB(A)
weight:	66 g
failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)
type:	ebmpapst 614 NHH-119
dimensions:	60x60x25 mm
tension:	24 V DC
power inout:	2.9 W
max. air volume:	56 m ³ /h
temperature range:	-20°C... +70°C
speed:	6,850 min ⁻¹
noise level:	41 dB(A)
weight:	66 g
failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)