

# Home - Fischerelektronik - LA 7

 [fischerelektronik.de/web\\_fischer/en\\_GB/VA/LA715012/datasheet.xhtml](http://fischerelektronik.de/web_fischer/en_GB/VA/LA715012/datasheet.xhtml)

## Features

width: 125 mm

height: 74 mm

length: 150 mm

thermal resistance: 0.11 - 0.05 K/W


surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor:

- 12 V DC
- 24 V DC

## Technical Drawing

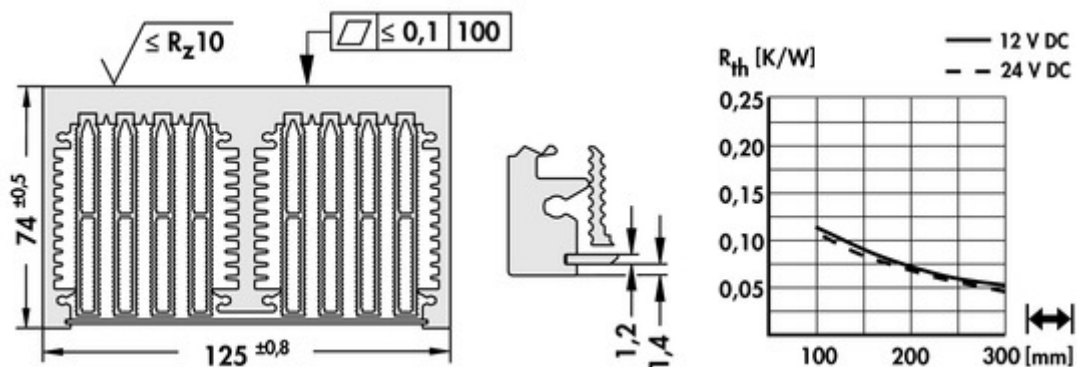

## Fan

type: ebmpapst 612 NHH-118

dimensions: 60x60x25 mm

|                                  |                                   |
|----------------------------------|-----------------------------------|
| tension:                         | 12 V DC                           |
| power inout:                     | 2.9 W                             |
| max. air volume:                 | 56 m <sup>3</sup> /h              |
| temperature range:               | -20°C... +70°C                    |
| speed:                           | 6,800 min <sup>-1</sup>           |
| noise level:                     | 41 dB(A)                          |
| weight:                          | 66 g                              |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 60,000 h (40°C) |
| type:                            | ebmpapst 614 NHH-119              |
| dimensions:                      | 60x60x25 mm                       |
| tension:                         | 24 V DC                           |
| power inout:                     | 2.9 W                             |
| max. air volume:                 | 56 m <sup>3</sup> /h              |
| temperature range:               | -20°C... +70°C                    |
| speed:                           | 6,850 min <sup>-1</sup>           |
| noise level:                     | 41 dB(A)                          |
| weight:                          | 66 g                              |
| failure rate (L <sub>10</sub> ): | L <sub>10</sub> > 60,000 h (40°C) |