

Home - Fischerelektronik - LA 9

 fischerelektronik.de/web_fischer/en_GB/VA/LA9300230/datasheet.xhtml

Features

width: 80 mm

height: 83 mm

length: 300 mm

thermal resistance: 0.28 - 0.12 K/W



surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor:

- 24 V DC
- 230 V AC

Technical Drawing

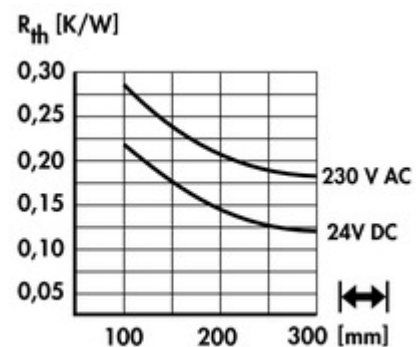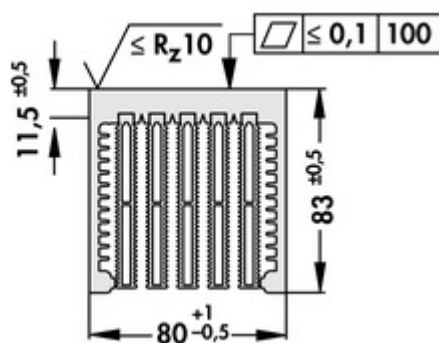

Fan

type: ebmpapst 8556N

dimensions: 80x80x38 mm

tension:	230 V AC
power inout:	12 W
max. air volume:	50 m ³ /h
temperature range:	-40°C... +90°C
speed:	2,800 min ⁻¹
noise level:	31 dB(A)
weight:	490 g
failure rate (L ₁₀):	L ₁₀ > 52,500 h (40°C)
type:	ebmpapst 8314H
dimensions:	80x80x32 mm
tension:	24 V DC
power inout:	6 W
max. air volume:	80 m ³ /h
temperature range:	-20°C... 75°C
speed:	5,000 min ⁻¹
noise level:	48 dB(A)
weight:	170 g
failure rate (L ₁₀):	L ₁₀ > 55,000 h (40°C)