

Home - Fischerelektronik - LA HL 3

fischerelektronik.de/web_fischer/en_GB/VA/LAHL3400/datasheet.xhtml



Data sheet Product LA HL 3 400

- [Print data sheet](#)
- [Recommend page](#)

Features

width: 129 mm

height: 115 mm

length: 400 mm


thermal resistance: 0.04 - 0.02 K/W

surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor: 230 V AC

Technical Drawing

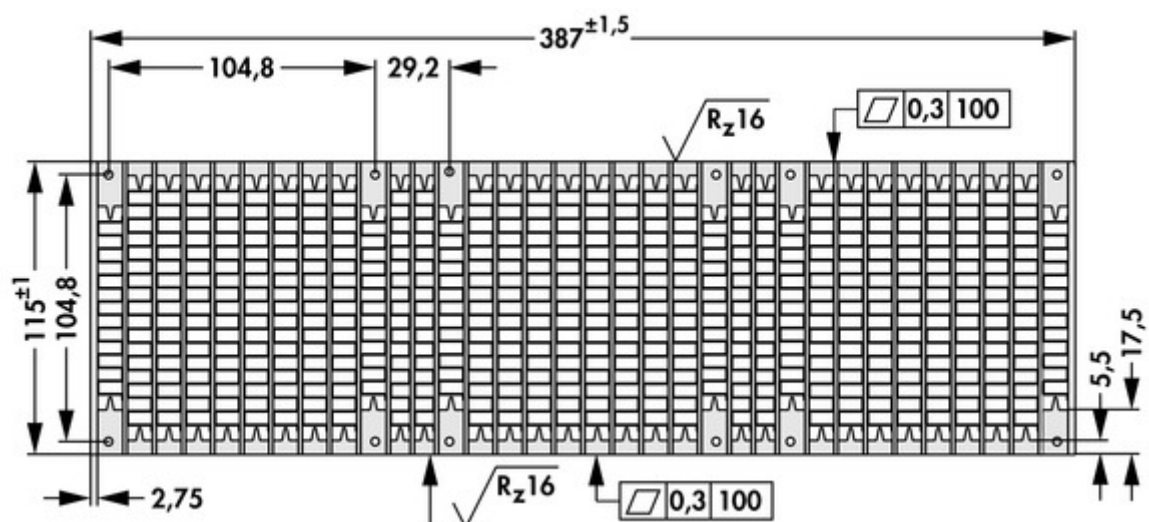

Fan

type:	ebmpapst 4656N
-------	----------------

dimensions:	119x119x38 mm
-------------	---------------

tension:	230 V AC
----------	----------

power inout:	19 W
--------------	------

max. air volume:	160 m ³ /h
------------------	-----------------------

temperature range:	-40°C... +85°C
--------------------	----------------

speed:	2,650 min ⁻¹
--------	-------------------------

noise level:	47 dB(A)
--------------	----------

weight:	550 g
---------	-------

failure rate (L ₁₀):	L ₁₀ > 37,500 h (40°C)
----------------------------------	-----------------------------------

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de