


Home - Fischerelektronik - LAHL D 1

 fischerelektronik.de/web_fischer/en_GB/VA/LAHL115012/datasheet.shtml

Features

width:	129 mm
height:	115 mm
length:	150 mm
thermal resistance:	0.08 - 0.045 K/W
operating voltage of the fan motor:	• 12 V DC • 24 V DC

Technical Drawing

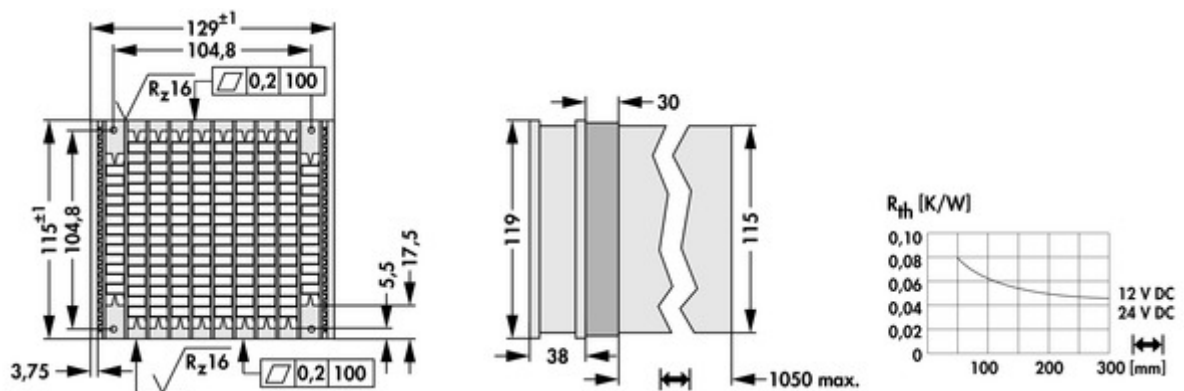

Fan

type:	ebmpapst 4112NH3
dimensions:	119x119x38 mm
tension:	12 V DC
power inout:	21 W

max. air volume:	310 m ³ /h
temperature range:	-20°C... +65°C
speed:	6,000 min ⁻¹
noise level:	65 dB(A)
weight:	390 g
failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C) L ₁₀ > 37,500 h (tmax)
type:	ebmpapst 4114NH3
dimensions:	119x119x38 mm
tension:	24 V DC
power inout:	19.5 W
max. air volume:	310 m ³ /h
temperature range:	-20°C... +65°C
speed:	6,000 min ⁻¹
noise level:	65 dB(A)
weight:	390 g
failure rate (L ₁₀):	L ₁₀ > 65,000 h (40°C) L ₁₀ > 37,500 h (tmax)