




Data sheet Product LA HLV 2 100 230

- [Print data sheet](#)
- [Recommend page](#)

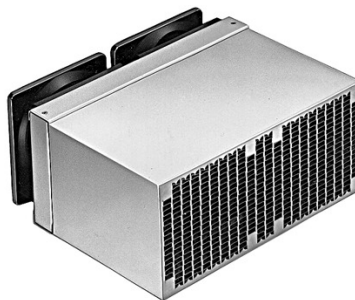

Cooling aggregates>Cooling aggregates with axial fan

258 x 115 mm, with axial fan and air-flow chamber

Features

width:	258 mm
--------	--------

height:	115 mm
---------	--------


length:	100 mm
---------	--------

thermal resistance:	0.079 - 0.055 K/W
---------------------	-------------------

surface:	• raw degreased aluminium (by the metre raw aluminium) • mounting area(s) milled flat
----------	---

operating voltage of the fan motor:	230 V AC
-------------------------------------	----------

Technical Drawing

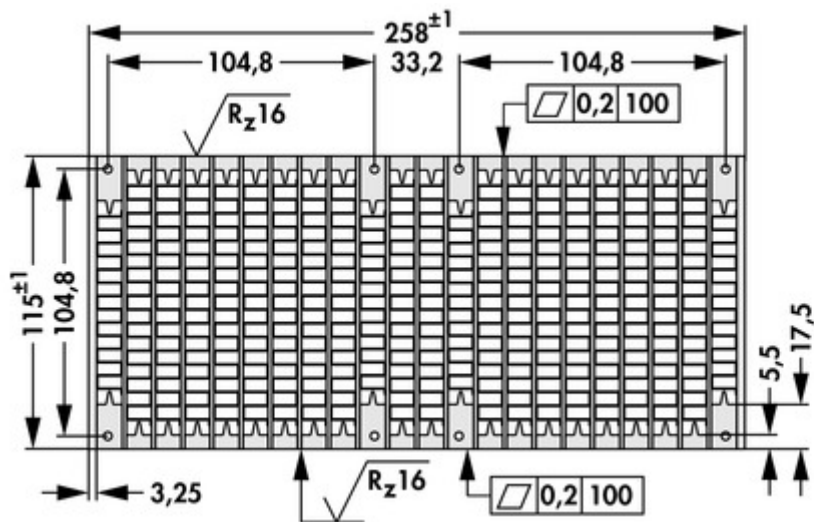

Fan

type:	ebmpapst 4656N
dimensions:	119x119x38 mm
tension:	230 V AC
power inout:	19 W
max. air volume:	160 m ³ /h
temperature range:	-40°C... +85°C
speed:	2,650 min ⁻¹
noise level:	47 dB(A)
weight:	550 g
failure rate (L ₁₀):	L ₁₀ > 37,500 h (40°C)