


Home - Fischerelektronik - LA HPK 3

 [fischerelektronik.de/web_fischer/en_GB/\\$catalogue/fischerData/PR/LA_HP3_/datasheet.xhtml](http://fischerelektronik.de/web_fischer/en_GB/$catalogue/fischerData/PR/LA_HP3_/datasheet.xhtml)

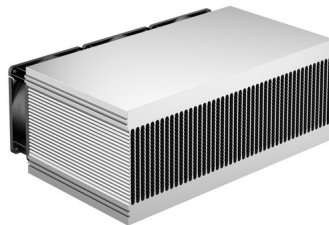


Cooling aggregates>Cooling aggregates with axial fan

- high performance cooling aggregates of special design
- optimal pressed in single lamellae
- low pressure losses due to adjusted fin geometry
- smallest fin spacings give a big heat exchange area
- maximum heatsink length 300 mm
- special designs according to drawing

Features

width:	282 mm
height:	110 mm
length:	100 mm
thermal resistance:	0.164 - 0.078 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 24 V DC • 230 V AC

Technical Drawing

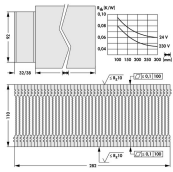

Fan

type: ebmpapst 3314 NHH

dimensions: 92x92x32 mm

tension: 24 V DC

power inout: 3.4 W

max. air volume: 107 m³/h

temperature range: -20°C... 75°C

speed: 3,450 min⁻¹

noise level: 42 dB(A)

weight: 190 g

failure rate (L₁₀): L₁₀ > 57,500 h (40°C)

type: ebmpapst 3656

dimensions: 92x92x38 mm

tension: 230 V AC

power inout: 12 W

max. air volume: 75 m³/h

temperature range: -40°C... +75°C

speed: 2,700 min⁻¹

noise level: 37 dB(A)

weight: 420 g

failure rate (L₁₀): L₁₀ > 52,500 h (40°C)

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de