




Data sheet Product LA V 10 250 24

- [Print data sheet](#)
- [Recommend page](#)

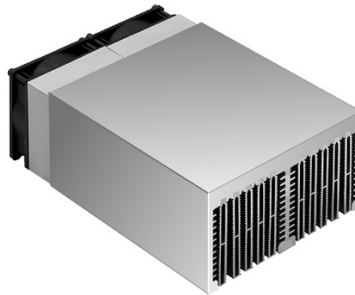

Cooling aggregates>Cooling aggregates with axial fan

160 x 83 mm, with axial fan and air-flow chamber

Features

width:	160 mm
--------	--------

height:	83 mm
---------	-------



length:	250 mm
---------	--------

thermal resistance:	0.185 - 0.062 K/W
---------------------	-------------------

surface:	• raw degreased aluminium (by the metre raw aluminium) • mounting area(s) milled flat
----------	---

operating voltage of the fan motor:	• 24 V DC • 230 V AC
-------------------------------------	--

Technical Drawing

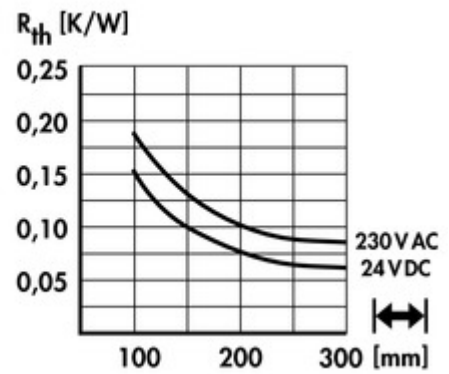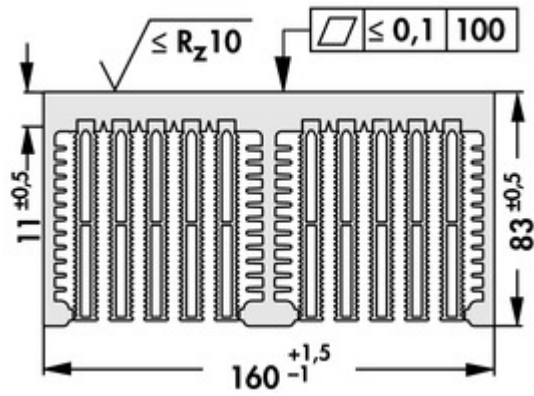

Fan

type:	ebmpapst 8556N
dimensions:	80x80x38 mm
tension:	230 V AC
power inout:	12 W
max. air volume:	50 m ³ /h
temperature range:	-40°C... +90°C
speed:	2,800 min ⁻¹
noise level:	31 dB(A)
weight:	490 g
failure rate (L ₁₀):	L ₁₀ > 52,500 h (40°C)