


Home - Fischerelektronik - LA V 11

fischerelektronik.de/web_fischer/en_GB/VA/LAV1130024/datasheet.xhtml

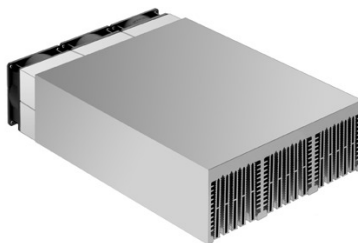

Cooling aggregates>Cooling aggregates with axial fan

240 x 83 mm, with axial fan and air-flow chamber

Features

width: 240 mm

height: 83 mm

length: 300 mm

thermal resistance: 0.11 - 0.046 K/W


surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor:

- 24 V DC
- 230 V AC

Technical Drawing

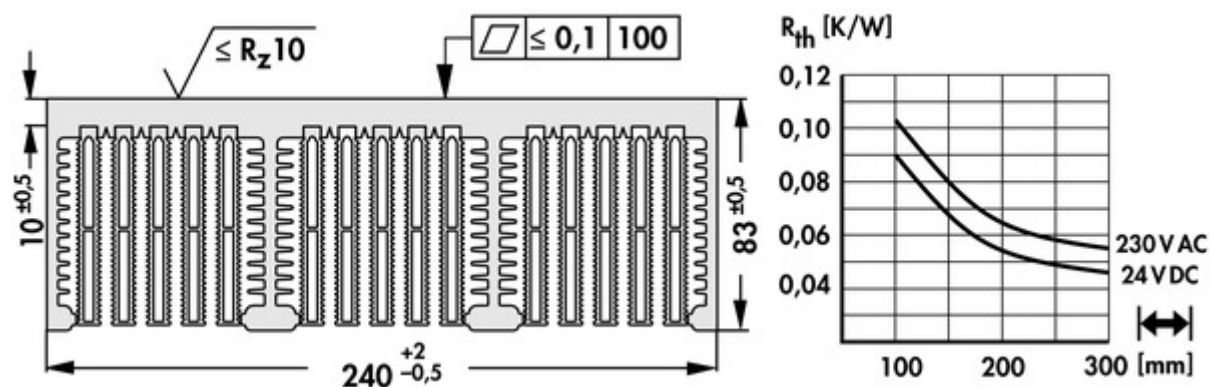

Fan

type:	ebmpapst 8556N
-------	----------------

dimensions:	80x80x38 mm
-------------	-------------

tension:	230 V AC
----------	----------

power inout:	12 W
--------------	------

max. air volume:	50 m ³ /h
------------------	----------------------

temperature range:	-40°C... +90°C
--------------------	----------------

speed:	2,800 min ⁻¹
--------	-------------------------

noise level:	31 dB(A)
--------------	----------

weight:	490 g
---------	-------

failure rate (L ₁₀):	L ₁₀ > 52,500 h (40°C)
----------------------------------	-----------------------------------

type:	ebmpapst 8314H
-------	----------------

dimensions:	80x80x32 mm
-------------	-------------

tension:	24 V DC
----------	---------

power inout:	6 W
--------------	-----

max. air volume:	80 m ³ /h
------------------	----------------------

temperature range:	-20°C... 75°C
--------------------	---------------

speed:	5,000 min ⁻¹
--------	-------------------------

noise level:	48 dB(A)
--------------	----------

weight:	170 g
---------	-------

failure rate (L ₁₀):	L ₁₀ > 55,000 h (40°C)
----------------------------------	-----------------------------------

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de