




Cooling aggregates>Cooling aggregates with axial fan

120 x 243 mm, with axial fan and air-flow chamber

Features

width:	243 mm
height:	120 mm
length:	200 mm
thermal resistance:	0.055 - 0.023 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 24 V DC • 230 V AC

Technical Drawing

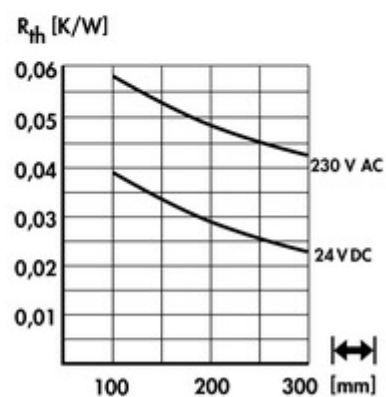

type:	ebmpapst 4184NXH
dimensions:	119x119x38 mm
tension:	24 V DC
power inout:	11 W
max. air volume:	237 m ³ /h
temperature range:	-30°C ... +70°C
speed:	4,400 min ⁻¹
noise level:	57 dB(A)
weight:	390 g
failure rate (L ₁₀):	L ₁₀ > 70,000 h (40°C)

type: ebmpapst 4656N

dimensions: 119x119x38 mm

tension: 230 V AC

power inout: 19 W

max. air volume: 160 m³/h

temperature range: -40°C... +85°C

speed: 2,650 min⁻¹

noise level: 47 dB(A)

weight: 550 g

failure rate (L₁₀): L₁₀ > 37,500 h (40°C)

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de