


Home - Fischerelektronik - LA V 21

 fischerelektronik.de/web_fischer/en_GB/VA/LAV2115024/datasheet.xhtml

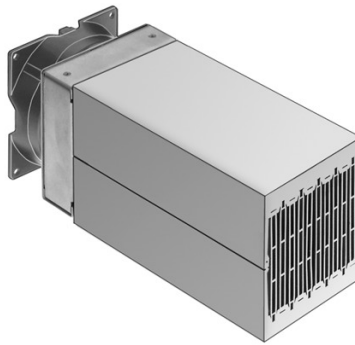

Cooling aggregates>Cooling aggregates with axial fan

92 x 92 mm, with axial fan and air-flow chamber

Features

width:	92 mm
--------	-------

height:	93 mm
---------	-------



length:	150 mm
---------	--------

thermal resistance:	0.18 - 0.07 K/W
---------------------	-----------------

surface:	• raw degreased aluminium (by the metre raw aluminium) • mounting area(s) milled flat
----------	---

operating voltage of the fan motor:	• 24 V DC • 230 V AC
-------------------------------------	--

Technical Drawing

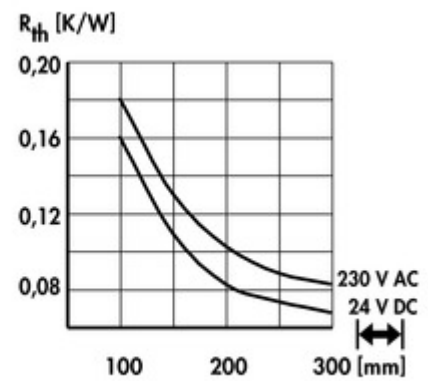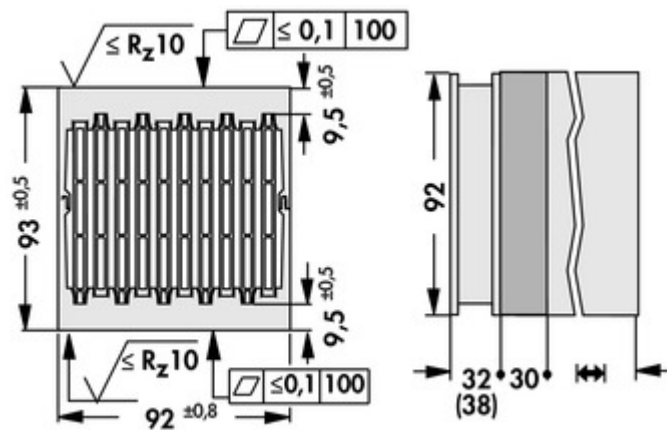

Fan

type: ebmpapst 3314 NHH

dimensions: 92x92x32 mm

tension: 24 V DC

power inout: 3.4 W

max. air volume: 107 m³/h

temperature range: -20°C... 75°C

speed: 3,450 min⁻¹

noise level: 42 dB(A)

weight: 190 g

failure rate (L₁₀): L₁₀ > 57,500 h (40°C)

type: ebmpapst 3656

dimensions: 92x92x38 mm

tension: 230 V AC

power inout:	12 W
max. air volume:	75 m ³ /h
temperature range:	-40°C... +75°C
speed:	2,700 min ⁻¹
noise level:	37 dB(A)
weight:	420 g
failure rate (L ₁₀):	L ₁₀ > 52,500 h (40°C)

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de