


Home - Fischerelektronik - LA V 6

 fischerelektronik.de/web_fischer/en_GB/VA/LAV630012/datasheet.xhtml

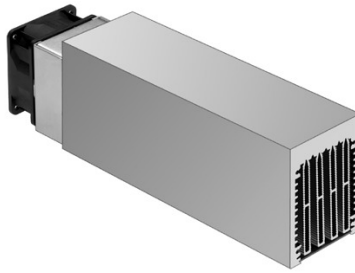

Cooling aggregates>Cooling aggregates with axial fan

62 x 74 mm, with axial fan and air-flow chamber

Features

width:	62 mm
--------	-------

height:	74 mm
---------	-------


length:	300 mm
---------	--------

thermal resistance:	0.175 - 0.095 K/W
---------------------	-------------------

surface:	• raw degreased aluminium (by the metre raw aluminium) • mounting area(s) milled flat
----------	---

operating voltage of the fan motor:	• 12 V DC • 24 V DC
-------------------------------------	---

Technical Drawing

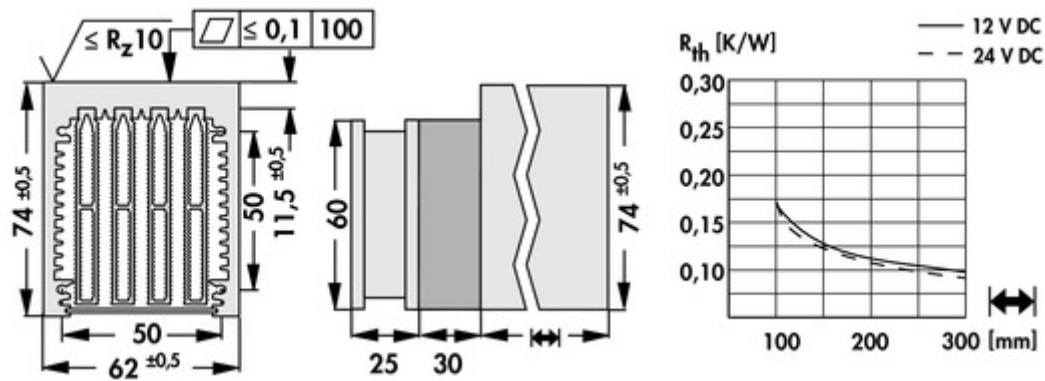

Fan

type: ebmpapst 612 NHH-118

dimensions: 60x60x25 mm

tension: 12 V DC

power inout: 2.9 W

max. air volume: 56 m³/h

temperature range: -20°C... +70°C

speed: 6,800 min⁻¹

noise level: 41 dB(A)

weight: 66 g

failure rate (L₁₀): L₁₀ > 60,000 h (40°C)

type: ebmpapst 614 NHH-119

dimensions: 60x60x25 mm

tension: 24 V DC

power inout:	2.9 W
max. air volume:	56 m ³ /h
temperature range:	-20°C... +70°C
speed:	6,850 min ⁻¹
noise level:	41 dB(A)
weight:	66 g
failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de