


Home - Fischerelektronik - LA V 7

 fischerelektronik.de/web_fischer/en_GB/VA/LAV710012/datasheet.xhtml

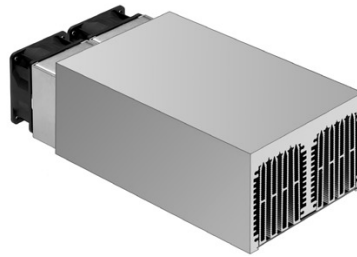

Cooling aggregates>Cooling aggregates with axial fan

125 x 74 mm, with axial fan and air-flow chamber

Features

width: 125 mm

height: 74 mm

length: 100 mm

thermal resistance: 0.1 - 0.04 K/W



surface:

- raw degreased aluminium (by the metre raw aluminium)
- mounting area(s) milled flat

operating voltage of the fan motor:

- 12 V DC
- 24 V DC

Technical Drawing

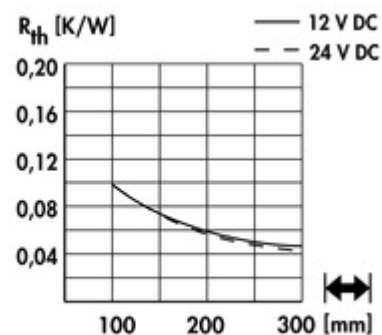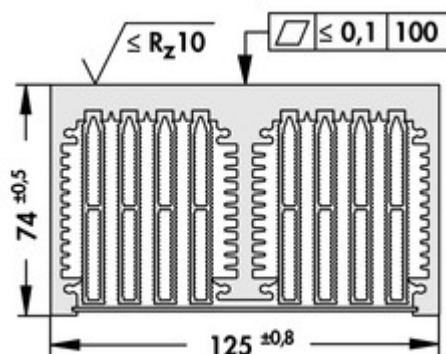

Fan

type:	ebmpapst 612 NHH-118
-------	----------------------

dimensions:	60x60x25 mm
-------------	-------------

tension:	12 V DC
----------	---------

power inout:	2.9 W
--------------	-------

max. air volume:	56 m ³ /h
------------------	----------------------

temperature range:	-20°C... +70°C
--------------------	----------------

speed:	6,800 min ⁻¹
--------	-------------------------

noise level:	41 dB(A)
--------------	----------

weight:	66 g
---------	------

failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)
----------------------------------	-----------------------------------

type:	ebmpapst 614 NHH-119
-------	----------------------

dimensions:	60x60x25 mm
-------------	-------------

tension:	24 V DC
----------	---------

power inout:	2.9 W
--------------	-------

max. air volume:	56 m ³ /h
------------------	----------------------

temperature range:	-20°C... +70°C
--------------------	----------------

speed:	6,850 min ⁻¹
--------	-------------------------

noise level:	41 dB(A)
--------------	----------

weight:	66 g
---------	------

failure rate (L ₁₀):	L ₁₀ > 60,000 h (40°C)
----------------------------------	-----------------------------------

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de