


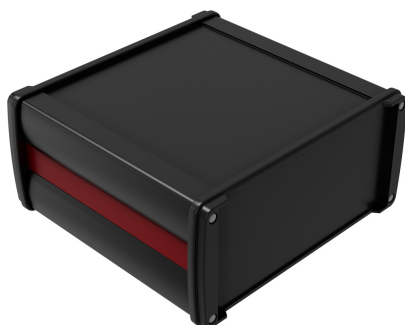

07503010

Profile Enclosure NoVoTronic

190 x 90 x 180 mm

Profile Enclosure NoVoTronic 190 x 90 x 180 mm

[Catalogues](#)[Assembly instructions](#)[Declaration of Conformity](#)[3D Data](#)

Technical data

Höhe	190 mm
Breite	90 mm
Tiefe	180 mm
Enclosure material	Gehäuseprofil: DIN EN 573 EN AW-AlMgSi, Gehäusedeckel: DIN EN 1706 EN AC-AISI 12 (Fe)
Colour Electronic Enclosure	Powder coating, Enclosure RAL 9005, jet black, function slide-in strips RAL 3003, ruby red
Ingress protection	IP65
Degree of protection norm	EN 60529
temperature min.	-40 °C
temperature max.	90 °C

Commercial data

Order unit	1 Piece
Customs tariff number	76169990
Weight	1.5 kg
GTIN	4250157902191

ETIM classification

ETIM 8	EC001031
--------	----------

ROSE SYSTEMTECHNIK GMBH
Erbeweg 13-15
32457 Porta Westfalica, Germany

Tel.: +49 571 50 41-0
Fax: +49 571 50 41-6
Mail: rose@rose-pw.de

Accessories

	07509005 Wall holder P160		07509111 Wall profile 130/160 - 130
	07509112 Wall profile 130/160 - 160		07509113 Wall profile 130/160 - 200
	07509114 Wall profile 130/160 - 300		83900003 Battery insert unit 9V block
	83900006 Battery insert unit 4x AA cells		