


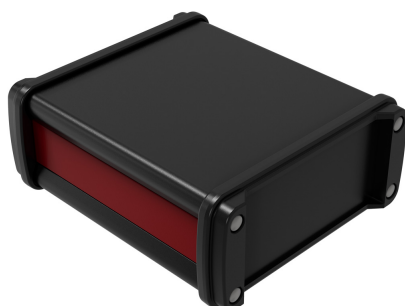

07501010

Profile Enclosure NoVoTronic

106 x 49 x 120 mm

Profile Enclosure NoVoTronic 106 x 49 x 120 mm

[Catalogues](#)[Assembly instructions](#)[Declaration of Conformity](#)[3D Data](#)

Technical data

Höhe	106 mm
Breite	49 mm
Tiefe	120 mm
Enclosure material	Gehäuseprofil: DIN EN 573 EN AW-ALMgSi, Gehäusedeckel: DIN EN 1706 EN AC-AISI 12 (Fe)
Colour Electronic Enclosure	Powder coating, Enclosure RAL 9005, jet black, function slide-in strips RAL 3003, ruby red
Ingress protection	IP65
Degree of protection norm	EN 60529
temperature min.	-40 °C
temperature max.	90 °C

Commercial data

Order unit	1 Piece
Customs tariff number	76169990
Weight	0.48 kg
GTIN	4250157902078

ETIM classification

ETIM 8	EC001031
--------	----------

ROSE SYSTEMTECHNIK GMBH
Erbeweg 13-15
32457 Porta Westfalica, Germany

Tel.: +49 571 50 41-0
Fax: +49 571 50 41-6
Mail: rose@rose-pw.de

Accessories



07509003

Wall holder P80



07509006

Mounting set C410 u. C420+A1705:D1716



07509011

Wall profile 80/100 - 100



07509012

Wall profile 80/100 - 160



07509013

Wall profile 80/100 - 200



83900003

Battery insert unit 9V block



83900006

Battery insert unit 4x AA cells