


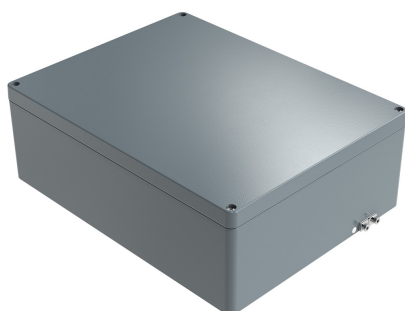

25314014

Aluminium Ex Enclosure Ex empty

312 x 403 x 141 mm

Aluminium Ex Enclosure Ex empty 312 x 403 x 141 mm

[Drawing](#)[3D Data](#)

Technical data

Höhe	312 mm
Breite	403 mm
Tiefe	141 mm
Material	Aluminium
Material quality	DIN EN 1706 EN AC-AISI 12 (Fe)
Colour	Silver gray (RAL 7001)
Ingress protection	IP66
Degree of protection norm	EN 60529
temperature min.	-55 °C
temperature max.	90 °C
Seal material	VMQ-(silicone)
Other versions on request	EMV, SBG, SWB, SBGL
Approvals	ABS, ATEX, CCOE India, EAC (TR CU), EXPLOLABS, IECEx, INMETRO, ISCVE Ukraine, UL Ex

Commercial data

Country of origin	IN
Order unit	1 Piece
Customs tariff number	85369095
Weight	7.44 kg
GTIN	4250157916099

ETIM classification

ETIM 8	EC002503
--------	----------

ROSE SYSTEMTECHNIK GMBH
Erbeweg 13-15
32457 Porta Westfalica, Germany

Tel.: +49 571 50 41-0
Fax: +49 571 50 41-6
Mail: rose@rose-pw.de

Accessories



10011020

Mounting plate for 01.314011



10022001

HINGE INTERNAL / STEEL



10027001

HINGE EXTERNAL / GREY



10061427

DIN rail 35/7,5 for xx.234011