

Screw-in tool

BIT-GKS-112 M-B

Item BIT-GKS-112M-B

 

 


GO TO PRODUCT

ingun[®]

Partner for Future Technology

INGUN SELECTION

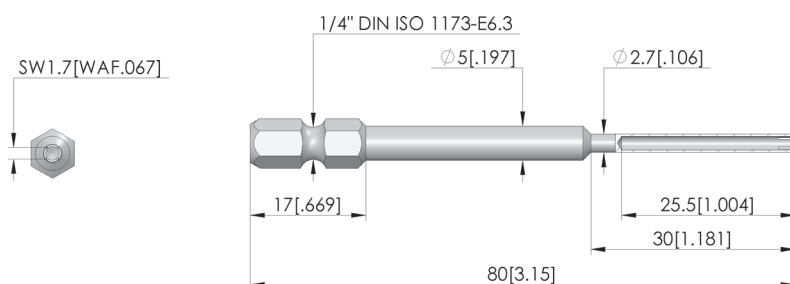

General data

Product group:	Bit inserts (BIT)
Compatible test probe(s) / receptacle(s):	007 GKS-112, GKS-427, GKS-746, GKS-761, HSS-118, HSS-827, SKS-215, T-112, GKS-204
Series:	BIT-GKS
Tool for receptacle (KS):	No
Tool for test probe (GKS):	Yes
Test probe installation type:	Screw-in
Min. tip diameter:	0 mm [0 in]
Max. tip diameter:	2 mm [.078 in]
Tool version:	Rigid
Screw-in torque:	3 - 5 cNm [.265 - .442 lbf·in]
RoHS-compliant:	RoHS-3

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Tool



ingun.com

TOOL