

Contact terminal

KT-158

Item 3650




GO TO PRODUCT

ingun[®]

Partner for Future Technology

INGUN SELECTION

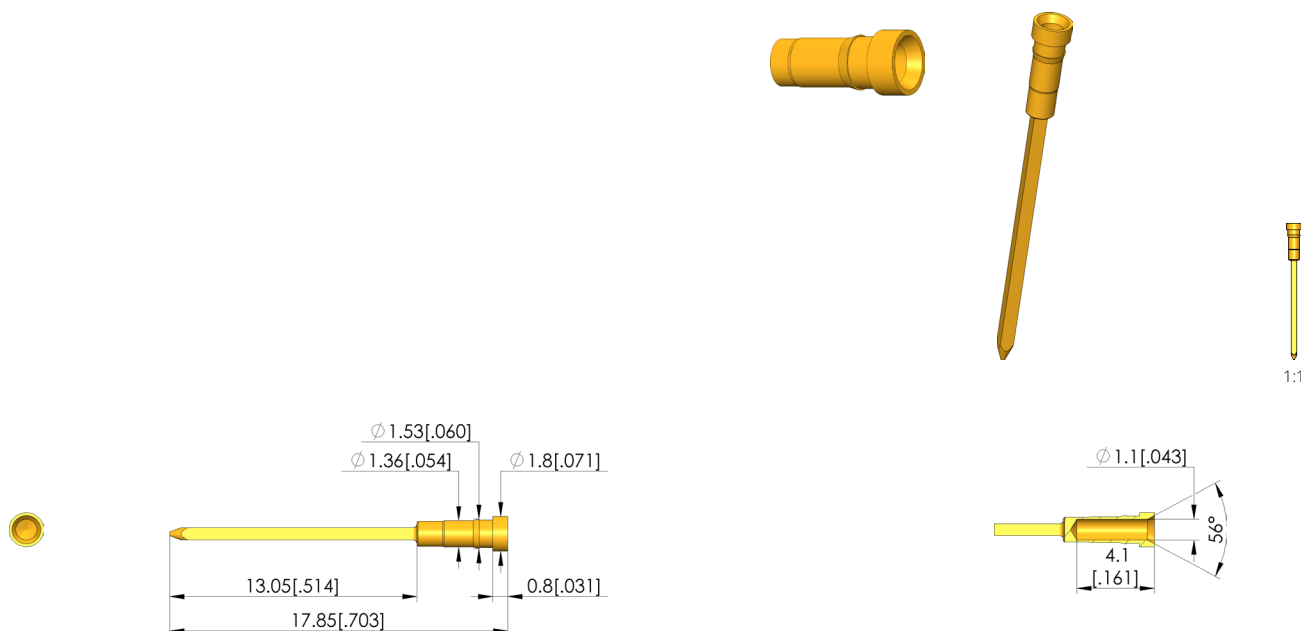

General data

Product group:

Series:

Sub-series:

Grid:

Type of contact terminal connection:

Magnetic:

Installation type:

Quick-exchange system:

Surface area:

Material:

Knurl:

RoHS-compliant:

Contact terminals (KT)

KT-158

KT-158

2.54 mm [100 mil]

Wire-wrap

Yes

Press-in

No

A gold

1 brass

No

RoHS-3;6c

Mounting hole

Mounting hole in CEM1:

Mounting hole in FR4:

1.44 - 1.46 mm [.056 - .057 in]

1.44 - 1.46 mm [.056 - .057 in]

Mechanical data

Collar height:

01

Total length:

17.8 mm [.700 in]

Shaft diameter:

1.35 mm [.053 in]

Latching lug:

Yes

Tip style data

Tip style:

43 inverse cone with chamfered bore

Tip diameter:

1.8 mm [.070 in]

Bore Ø in tip style:

1.1 mm [.043 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162

78467, Constance, Germany

Phone +49 7531 8105-0

Customer hotline +49 7531 8105-888

Fax +49 7531 8105-65

info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com