

Receptacle A

KS-112 30 M-R

Item KS-11230M-R




GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION

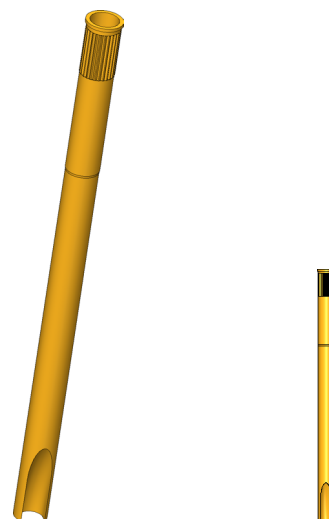

1:1

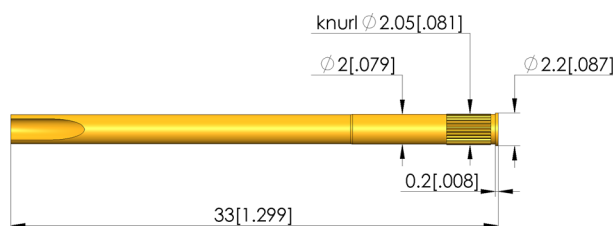

General data

Product group:
 Series:
 Sub-series:
 Type of receptacle connection:
 Press ring:
 Surface area:
 Collar diameter:
 Collar height:
 Knurl:
 Vacuum-tight:
 RoHS-compliant:

Receptacles (KS)
 KS-112
 KS-112 M screw-in version
 Solder
 No
 Gold
 2.2 mm [.086 in]
 0.2 mm [.007 in]
 Yes
 No
 RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
 Mounting hole in FR4:

2.00 - 2.02 mm [.078 - .079 in]
 2.00 - 2.02 mm [.078 - .079 in]

Mechanical data

Total length:
 Outer diameter:

33 mm [1.29 in]
 2 mm [.078 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
 78467, Constance, Germany
 Phone +49 7531 8105-0
 Customer hotline +49 7531 8105-888
 Fax +49 7531 8105-65
 info@ingun.com



Prices and delivery times on request.
 Technical changes reserved. 04/24_GB

Learn more about
 Test probes



ingun.com