

Receptacle

KS-113 30 M2-R-S

Item KS-11330M2-R-S




GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION

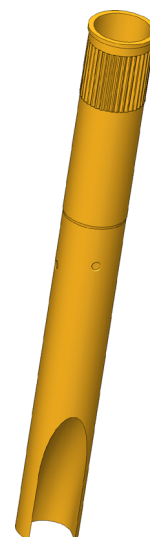

1:1

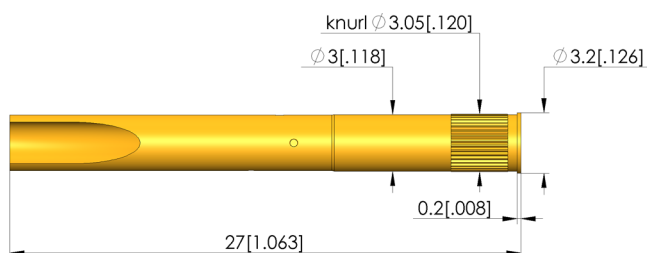

General data

Product group:
Series:
Sub-series:
Type of receptacle connection:
Press ring:
Surface area:
Collar diameter:
Collar height:
Knurl:
Vacuum-tight:
RoHS-compliant:

Receptacles (KS)
KS-113
KS-113 M screw-in version
Solder
No
Gold
3.2 mm [.125 in]
0.2 mm [.007 in]
Yes
No
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

3.00 - 3.02 mm [.118 - .118 in]
3.00 - 3.02 mm [.118 - .118 in]

Mechanical data

Total length:
Outer diameter:

27 mm [1.06 in]
3 mm [.118 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com