

Contact terminal, high-current KT-2259


Item KT-2259




GO TO PRODUCT

ingun[®]

Partner for Future Technology

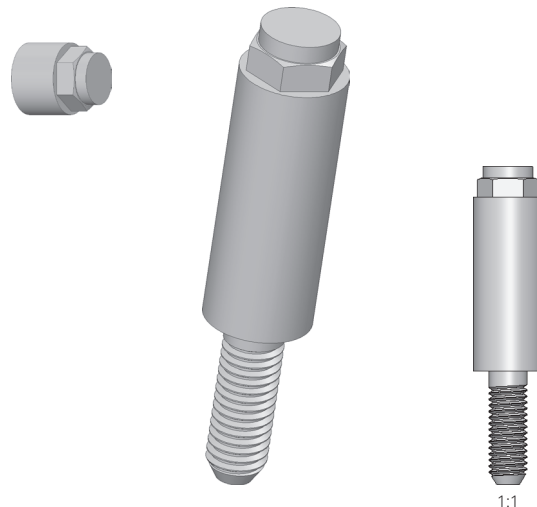

1:1

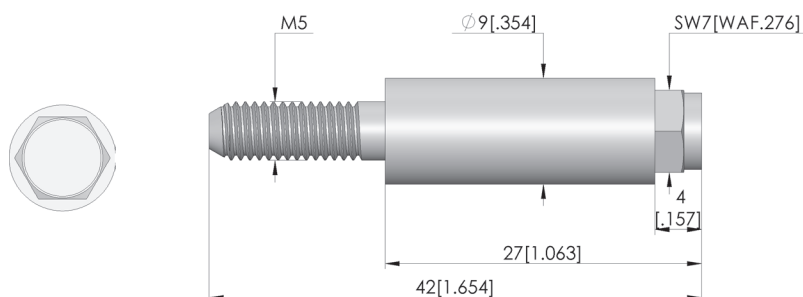

General data

Product group:
Series:
Sub-series:
Grid:
Type of contact terminal connection:
Magnetic:
Installation type:
Quick-exchange system:
Surface area:
Material:
Knurl:
RoHS-compliant:

Contact terminals (KT)
KT-2259
KT-2259
10 mm [393 mil]
Thread connection
No
Screw-in
No
S silver
1 brass
No
RoHS-3

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

5.10 - 5.50 mm [.200 - .216 in]
5.10 - 5.50 mm [.200 - .216 in]

Mechanical data

Total length: 42 mm [1.65 in]
Shaft diameter: 9 mm [.354 in]
Latching lug: No

Tip style data

Tip style: 02 flat
Tip diameter: 6.5 mm [.255 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com

CONTACT TERMINALS