

Contact terminal, high-current KT-2513


Item KT-2513





GO TO PRODUCT

ingun[®]

Partner for Future Technology

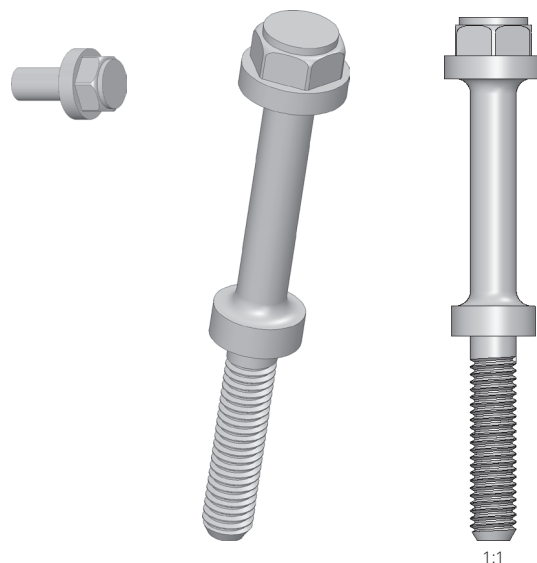

1:1

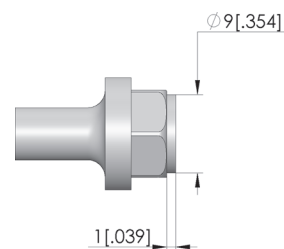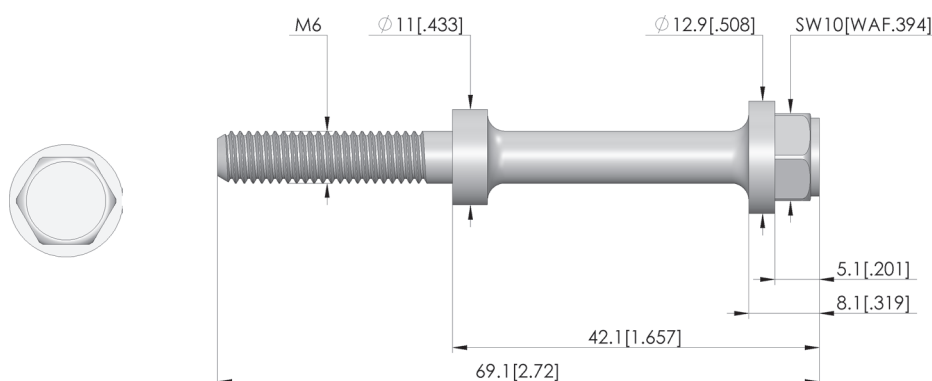

General data

Product group:
Series:
Sub-series:
Grid:
Type of contact terminal connection:
Magnetic:
Installation type:
Quick-exchange system:
Surface area:
Material:
Knurl:
RoHS-compliant:

Contact terminals (KT)
KT-2513
KT-2513
14 mm [551 mil]
Thread connection
No
Screw-in
No
S silver
1 brass
No
RoHS-3

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

6.10 - 6.50 mm [.240 - .255 in]
6.10 - 6.50 mm [.240 - .255 in]

Mechanical data

Total length:
Shaft diameter:
Latching lug:

69.1 mm [2.72 in]
12.9 mm [.507 in]
No

Tip style data

Tip style:
Tip diameter:

02 flat
9 mm [.354 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes

