

KS for SKS-415 ... 02 E

KS-415 S

Item KS-415S




GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION

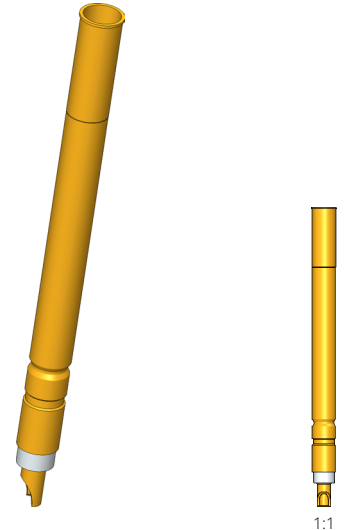

1:1

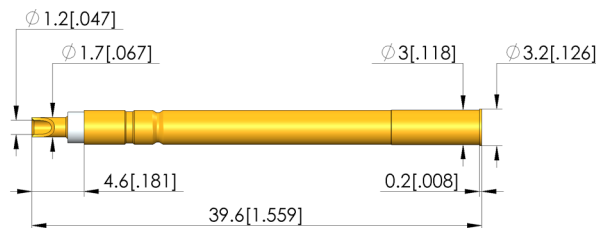

General data

Product group:	Receptacles (KS)
Series:	KS-415
Sub-series:	KS-415 S press-in version, quick-exchange system
Type of receptacle connection:	Plug / open
Press ring:	No
Surface area:	Gold
Collar diameter:	3.2 mm [.125 in]
Collar height:	0.2 mm [.007 in]
Knurl:	No
Vacuum-tight:	No
RoHS-compliant:	RoHS-3;6c

Mounting hole

Mounting hole in CEM1:	2.98 - 2.99 mm [.117 - .117 in]
Mounting hole in FR4:	2.98 - 2.99 mm [.117 - .117 in]

Mechanical data

Total length:	39.6 mm [1.55 in]
Outer diameter:	3 mm [.118 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com

RECEPTACLES