

Contact terminal A KT-254 L3 E02-30

Item KT-254L3E02-30






GO TO PRODUCT

ingun[®]

Partner for Future Technology

INGUN SELECTION

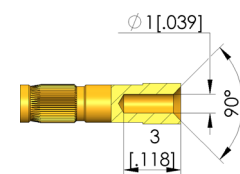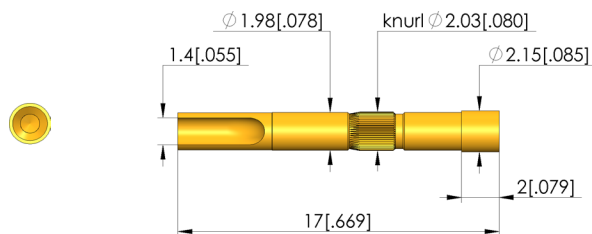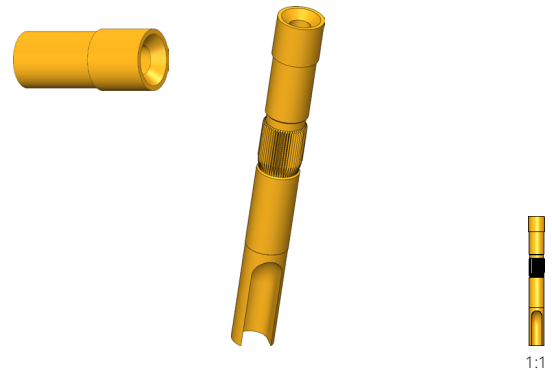

General data

Product group:	Contact terminals (KT)
Series:	KT-254
Sub-series:	KT-254
Grid:	2.54 mm [100 mil]
Type of contact terminal connection:	Solder connection
Magnetic:	Yes
Installation type:	Press-in
Quick-exchange system:	No
Surface area:	A gold
Material:	1 brass
Knurl:	Yes
RoHS-compliant:	RoHS-3;6c

Mounting hole

Mounting hole in CEM1:	1.98 - 2.00 mm [.077 - .078 in]
Mounting hole in FR4:	1.98 - 1.99 mm [.077 - .078 in]

Mechanical data

Collar height:	02
Total length:	17 mm [.669 in]
Shaft diameter:	1.98 mm [.077 in]
Latching lug:	No

Tip style data

Tip style:	43 inverse cone with chamfered bore
Tip diameter:	2.15 mm [.084 in]
Bore ϕ in tip style:	1 mm [.039 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com

CONTACT TERMINALS