

# Contact terminal A

## KT-254 L3 E02


Item KT-254L3E02





GO TO PRODUCT

**ingun**<sup>®</sup>

Partner for Future Technology

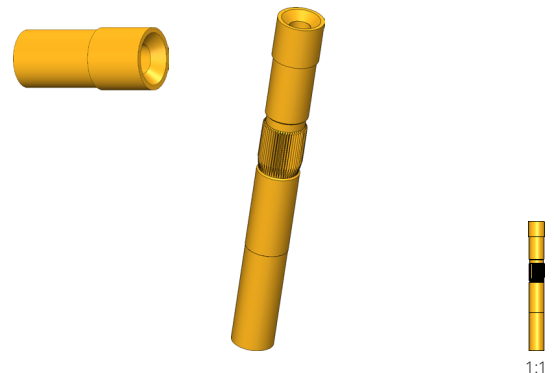

1:1

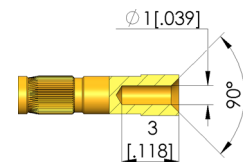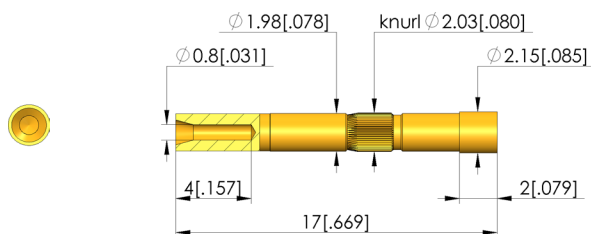

### General data

Product group:  
Series:  
Sub-series:  
Grid:  
Type of contact terminal connection:  
Magnetic:  
Installation type:  
Quick-exchange system:  
Surface area:  
Material:  
Knurl:  
RoHS-compliant:

Contact terminals (KT)  
KT-254  
KT-254  
2.54 mm [100 mil]  
Solder connection  
Yes  
Press-in  
No  
A gold  
1 brass  
Yes  
RoHS-3;6c

### Mounting hole

Mounting hole in CEM1:  
Mounting hole in FR4:

1.98 - 2.00 mm [.077 - .078 in]  
1.98 - 1.99 mm [.077 - .078 in]

### Mechanical data

Collar height:  
Total length:  
Shaft diameter:  
Latching lug:

02  
17 mm [.669 in]  
1.98 mm [.077 in]  
No

### Tip style data

Tip style:  
Tip diameter:  
Bore  $\phi$  in tip style:

43 inverse cone with chamfered bore  
2.15 mm [.084 in]  
1 mm [.039 in]

### INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162  
78467, Constance, Germany  
Phone +49 7531 8105-0  
Customer hotline +49 7531 8105-888  
Fax +49 7531 8105-65  
info@ingun.com



Prices and delivery times on request.  
Technical changes reserved. 04/24\_GB

Learn more about  
Test probes



ingun.com