

Contact terminal A

KT-254 W3 E02




Item KT-254W3E02



GO TO PRODUCT

ingun[®]

Partner for Future Technology

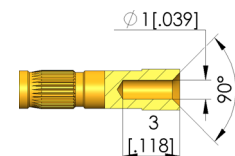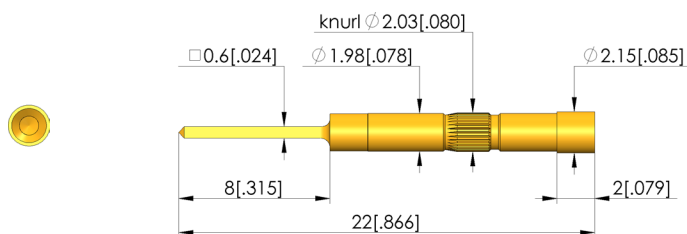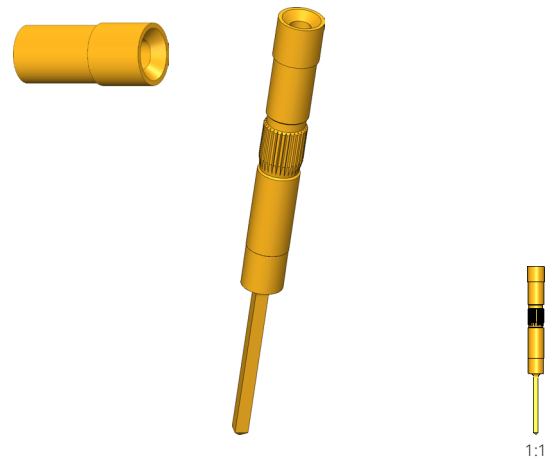

General data

Product group:
Series:
Sub-series:
Grid:
Type of contact terminal connection:
Magnetic:
Installation type:
Quick-exchange system:
Surface area:
Material:
Knurl:
RoHS-compliant:

Contact terminals (KT)
KT-254
KT-254
2.54 mm [100 mil]
Wire-wrap
Yes
Press-in
No
A gold
1 brass
Yes
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

1.98 - 2.00 mm [.077 - .078 in]
1.98 - 1.99 mm [.077 - .078 in]

Mechanical data

Collar height:
Total length:
Shaft diameter:
Latching lug:

02
22 mm [.866 in]
1.98 mm [.077 in]
No

Tip style data

Tip style:
Tip diameter:
Bore ϕ in tip style:

43 inverse cone with chamfered bore
2.15 mm [.084 in]
1 mm [.039 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com