

Receptacle

KS-465 M2.5 E05-F-R

Item KS-465M2.5E05-F-R




GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION

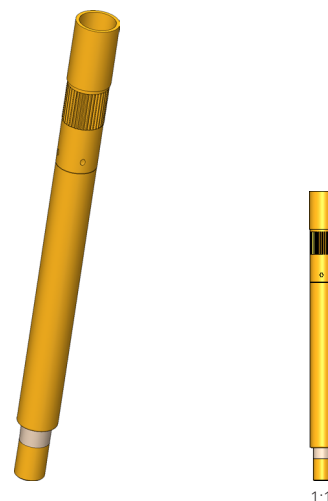

1:1

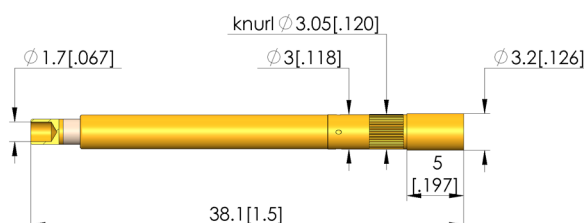

General data

Product group:	Receptacles (KS)
Series:	KS-465
Sub-series:	KS-465 M-F, screw-in version quick-exchange system
Type of receptacle connection:	Plug / open
Press ring:	No
Surface area:	Gold
Collar diameter:	3.2 mm [.125 in]
Collar height:	5 mm [.196 in]
Knurl:	Yes
Vacuum-tight:	No
RoHS-compliant:	RoHS-3;6c

Mounting hole

Mounting hole in CEM1:	3.00 - 3.02 mm [.118 - .118 in]
Mounting hole in FR4:	3.00 - 3.02 mm [.118 - .118 in]

Mechanical data

Total length:	38.1 mm [1.5 in]
Outer diameter:	3 mm [.118 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com

RECEPTACLES