

Receptacle

KS-465 M2.5 E05

Item KS-465M2.5E05

 


GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION



1:1

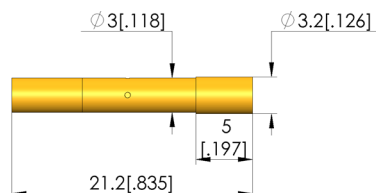

General data

Product group:
Series:
Sub-series:
Type of receptacle connection:
Press ring:
Surface area:
Collar diameter:
Collar height:
Knurl:
Vacuum-tight:
RoHS-compliant:

Receptacles (KS)
KS-465
KS-465 M, screw-in version
Solder outer surface
No
Gold
3.2 mm [.125 in]
5 mm [.196 in]
No
No
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

2.98 - 2.99 mm [.117 - .117 in]
2.98 - 2.99 mm [.117 - .117 in]

Mechanical data

Total length:
Outer diameter:

21.2 mm [.834 in]
3 mm [.118 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com