

Contact terminal A

KT-279 102 300

Item KT-279102300

 


GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION



1:1

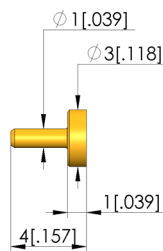

General data

Product group:
Series:
Sub-series:
Grid:
Type of contact terminal connection:
Magnetic:
Installation type:
Quick-exchange system:
Surface area:
Material:
Knurl:
RoHS-compliant:

Contact terminals (KT)
KT-279
KT-279
3.5 mm [137 mil]
Solder connection
Yes
Press-in
No
A gold
1 brass
No
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

0.98 - 0.99 mm [.038 - .038 in]
0.98 - 0.99 mm [.038 - .038 in]

Mechanical data

Collar height:
Total length:
Shaft diameter:
Latching lug:

01
4 mm [.157 in]
1 mm [.039 in]
No

Tip style data

Tip style:
Tip diameter:

02 flat
3 mm [.118 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com

CONTACT TERMINALS