

Contact terminal R

KT-586 102 400 R

Item KT-586102400R




GO TO PRODUCT

ingun[®]

Partner for Future Technology

INGUN SELECTION

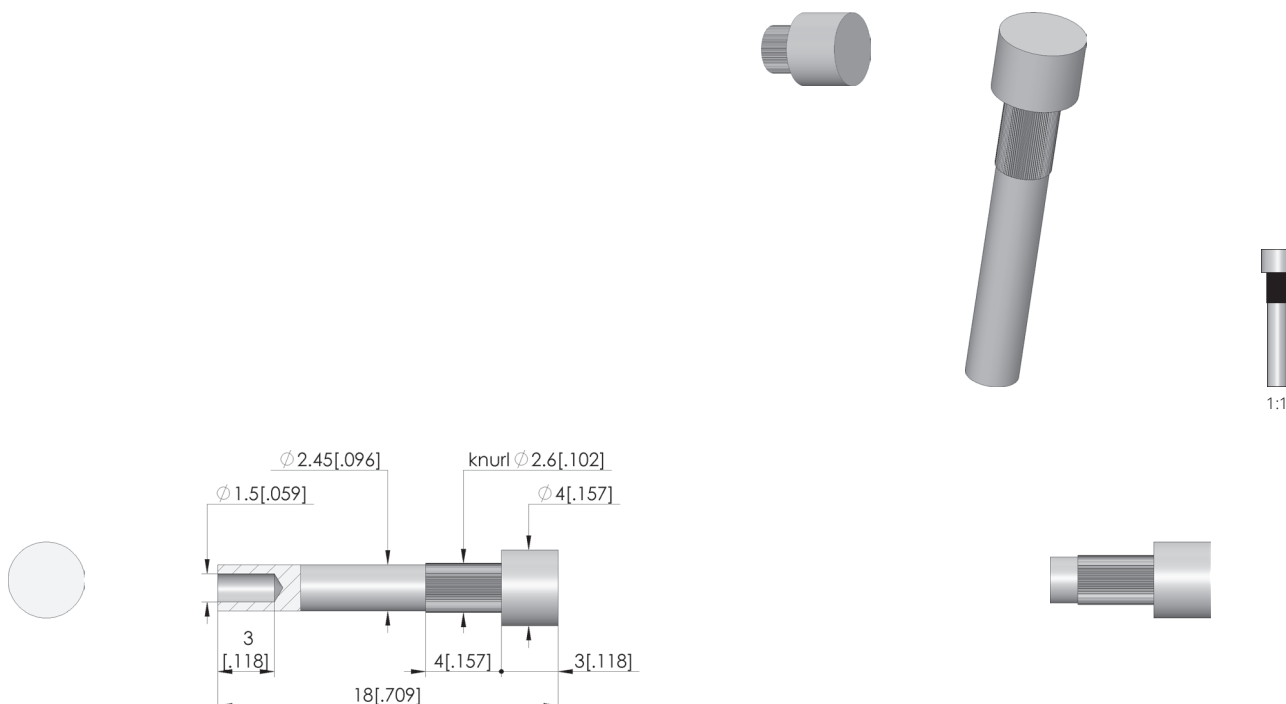

General data

Product group:
Series:
Sub-series:
Grid:
Type of contact terminal connection:
Magnetic:
Installation type:
Quick-exchange system:
Surface area:
Material:
Knurl:
RoHS-compliant:

Contact terminals (KT)
KT-586
KT-586
4.5 mm [177 mil]
Solder connection
Yes
Press-in
No
R rhodium
1 brass
Yes
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

2.55 - 2.57 mm [.100 - .101 in]
2.55 - 2.57 mm [.100 - .101 in]

Mechanical data

Collar height:
Total length:
Shaft diameter:
Latching lug:

03
18 mm [.708 in]
2.45 mm [.096 in]
No

Tip style data

Tip style:
Tip diameter:

02 flat
4 mm [.157 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 04/24_GB

Learn more about
Test probes



ingun.com