



Compatible With Lithium
IMR 3.6V/3.7V Batteries:

10440	18500
14500	18650
16340	26500
17340	26650
18350	20700
18490	21700

DC input power	----- DC 12V2A
2*2.0A CC current	----- 2000mA±10%
4*1.0A CC current	----- 1000mA±10%
8*0.5A CC current	----- 500mA±10%
Auto cut-off voltage	----- 4.20±0.05V
CV cut-off current	----- < 10% max
Standby current	----- <100mA
Activation current (battery voltage<2.90V)	--- 10mA~100 mA
Auto recharge voltage	----- 4.10±0.10V
Operation Temperature	----- 0°C ~ 40°C
Storage Temperature	----- -40°C ~ +70°C



CONVENIENT CHARGING FOR ANYWHERE YOU WANT AND ANYTIME YOU NEED.




DESCRIPTION

Efest LUSH Q8 LED Indicator Charger

- Fashion, modern and curve appearance
- Stylish & eye catching packaging
- High quality fire retardant material

FEATURES

- Automatic selective charging modes:
8×0.5A/4×1.0A/2×2.0A
- 2A fast charging current works on Slot 1 & Slot 8
- 4 kinds of protection: over-discharging,
over-voltage, short-circuit and reverse polarity protection
- Low voltage smart activation recovery function($\geq 0.6V$)

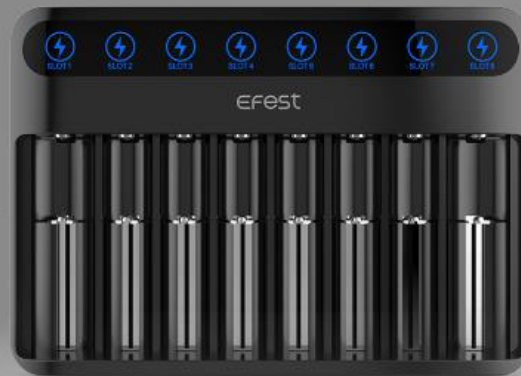

CRAFTSMANSHIP

- Spring made by piano wire, it provides a smooth sliding action when installing and removing batteries.
- Steel cathode with low resistance and hard chromium plating processing to achieve a more precise charging voltage.
- 15,000+ times spring testing quality warranty



CERTIFICATIONS



Global Insurance technical support with
FCC, CE, RoHS certification.

PACKAGE



WARNING

