


4-way adhesive backed mounts for cable ties

BN 20345

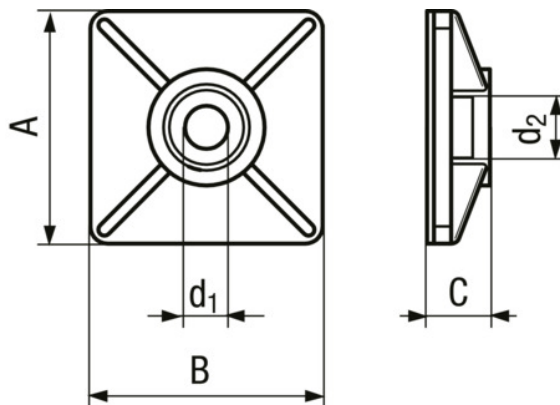

Product features

- UV stability: low
- Operating temperature range: -35 °C ... +85 °C
- Material flammability rating: UL94V-2

Material Polyamide

Material execution PA 6.6

Color black

b) Slot: d1 4 = 4 x 1,2 mm / d1 5 = 5 x 1,5 mm

Article no.	Length (A)	Width (B)	C	d1	d2
3389416	19	19	5	4	3,5
3389417	28	28	5,5	5	4,6