

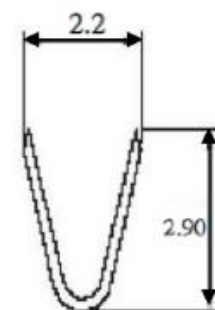


■ TERMINAL

- Material : Phos. bronze
- Thickness : 0.2mm
- Plating : Tin Plated 60u"
- Wire Range : Suitable for AWG 22-28
- Insulation O.D. : 1.4mm (max)
- Q'TY : 10,000 pcs/Reel

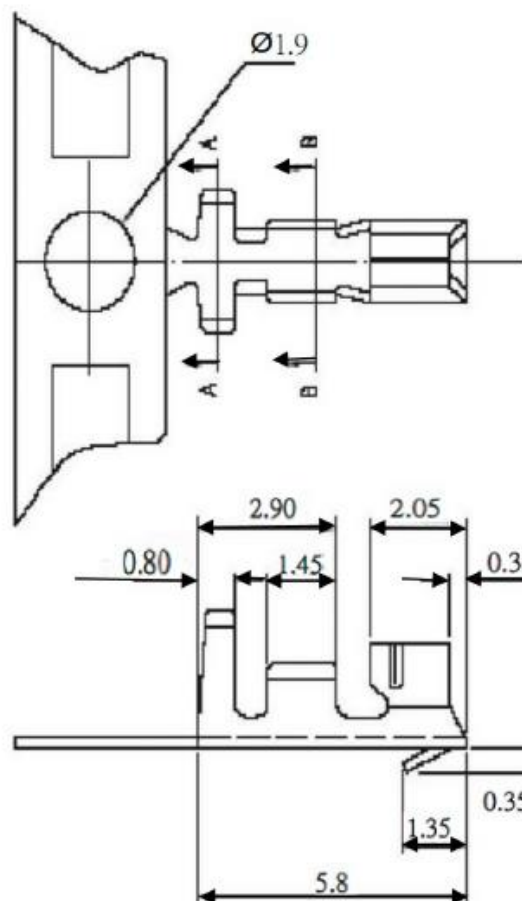

A - A SECTION

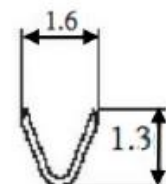

B - B SECTION

**RoHS
Compliant**

Ninigi

 
APPD.
核准

DWG.
製圖

DATE 制表日

2019/10/16

Hedy



SCALE
比例 參考

UNIT
單位 MM

PAGE
張數 1 / 1

TOLERANCE
容許公差
0 ± 0.2
.00 ±
ANG. ±

SIZE.
紙張尺寸 A 4

REV.
版次 B

PART NAME 品名

2.0mm TERMINAL PHOSPHOR
BRONZE MATERIAL TIN PLATED
SUITABLE AWG22~28 1R=10K PCS ROHS

PART NO.

料號

NXG-T