


DIN 127 B

Spring lock washers type B

Podkładki sprężyste, typ B

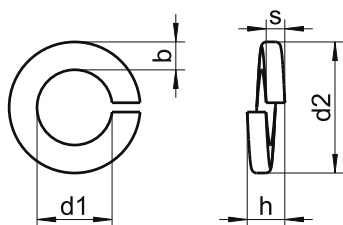

d1	for	d max	h min.	s	b
2,1	M2	4,4	1,0	0,5	0,9
2,6	M2,5	5,1	1,2	0,6	1,0
3,1	M3	6,2	1,6	0,8	1,3
3,6	M3,5	6,7	1,6	0,8	1,3
4,1	M4	7,6	1,8	0,9	1,5
5,1	M5	9,2	2,4	1,2	1,8
6,1	M6	11,8	3,2	1,6	2,5
7,1	M7	12,8	3,2	1,6	2,5
8,1	M8	14,8	4,0	2,0	3,0
10,2	M10	18,1	4,4	2,2	3,5
12,2	M12	21,1	5,0	2,5	4,0
14,2	M14	24,1	6,0	3,0	4,5
16,2	M16	27,4	7,0	3,5	5,0
18,2	M18	29,4	7,0	3,5	5,0
20,2	M20	33,6	8,0	4,0	6,0
22,5	M22	35,9	8,0	4,0	6,0
24,5	M24	40,0	10,0	5,0	7,0
27,5	M27	43,0	10,0	5,0	7,0
30,5	M30	48,2	12,0	6,0	8,0
33,5	M33	55,2	12,0	6,0	10,0
36,5	M36	58,2	12,0	6,0	10,0
39,5	M39	61,2	12,0	6,0	10,0
42,5	M42	68,2	14,0	7,0	12,0
45,5	M45	71,2	14,0	7,0	12,0
49,0	M48	75,0	14,0	7,0	12,0

■ A1 / ■ A2 / ■ A4

MAT.	BOX
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	1000
1.4310 / ■	500
1.4310 / ■	500
1.4310 / ■	500
1.4310 / ■	500
1.4310 / ■	200
1.4310 / ■	200
1.4310 / ■	100
1.4310 / ■	100
1.4310 / ■	50
1.4310 / ■	50
1.4310 / ■	50
1.4310 / ■	25
1.4310 / ■	25
1.4310 / ■	25
1.4310 / ■	25