
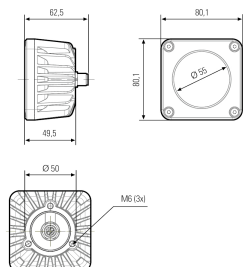
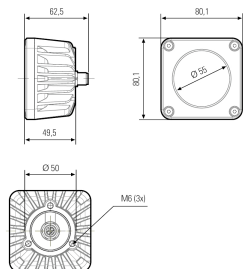


LED Maschinenleuchte

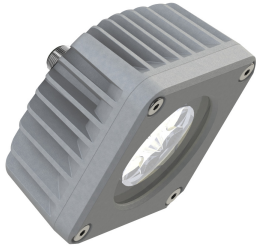

Product-Nr.	121013-04
EAN:	4260556625737
Model:	CENALED SPOT Aufbau
Order number:	121013-04
Model:	CENALED SPOT Aufbau
Type:	surface-mounted LED light
Illuminant:	High Power LED
Power consumption:	~8,5 W
Lamp luminous flux:	1120 lm
Lamp luminous efficiency:	134 lm/W
Light distribution:	direct
Light colour:	neutral white (5000K)
Connected load:	24V DC $\pm$ 10%
Connection (connector):	M12 A-coded
Degree of protection:	IP67
Class of protection:	III
Beam angle (optics):	65°
Operating temperature:	-10... +50 °C (14... 122 °F)
Colour rendering (Ra):	>80
Lamps lifetime:	> 60.000 h (L80/B10)
Housing material:	aluminium (powder-coated)
Cover material:	safety glass 4 mm (0,16"), crack-resistant
Height [B] x Width [C]:	cubic measure: ~80 mm x 80 mm x 62.5 mm (~3,15 x 3,15 x 2,46")
Weight (net):	400 g (~14 oz)
Gross weight:	500 g (~18 oz)
Risk group (DIN EN 62471):	free group
Markings:	CE, UKCA, ETL Listed (5003526)
Dimmable:	optional via accessories
Mounting accessories:	articulated joint 214300-01 as holder optional
Made in:	Germany
Feature:	65° optics for full flat light
Note:	seal included; mounting: 3x M6 screws at rear