
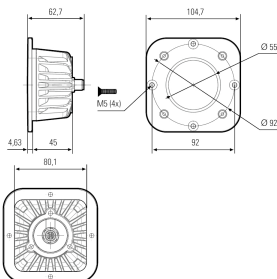
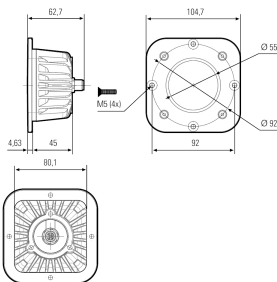
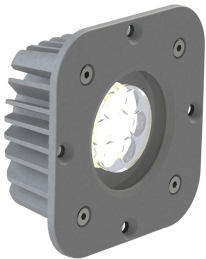


LED Maschinenleuchte

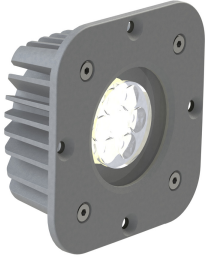

Product-Nr.	121012-05
EAN:	4260556625751
Model:	CENALED SPOT Einbau
Order number:	121012-05
Model:	CENALED SPOT Einbau
Type:	LED recessed light
Illuminant:	High Power LED
Power consumption:	~8,5 W
Lamp luminous flux:	1120 lm
Lamp luminous efficiency:	134 lm/W
Light distribution:	direct
Light colour:	neutral white (5000K)
Connected load:	24V DC $\pm$ 10%
Connection (connector):	M12 A-coded
Degree of protection:	IP67
Class of protection:	III
Beam angle (optics):	30°
Operating temperature:	-10... +50 °C (14... 122 °F)
Colour rendering (Ra):	>80
Lamps lifetime:	> 60.000 h (L80/B10)
Housing material:	aluminium (powder-coated)
Cover material:	safety glass 4 mm (0,16"), crack-resistant
Height [B] x Width [C]:	installation body: ~80 mm x 80 mm (~3,15" x 3,15"), installation depth >60 mm (>2,36"), cover ~105 mm x 105 mm, ~5 mm (~4,13" x 4,13" x 0,2") built-up
Weight (net):	450 g (~16 oz)
Gross weight:	550 g (~19 oz)
Risk group (DIN EN 62471):	free group
Markings:	CE, UKCA, ETL Listed (5003526)
Dimmable:	optional via accessories
Made in:	Germany
Feature:	30° optics for flat light
Note:	seal included in delivery; fastening via 4 countersunk bolts M5