

Top-Tier Gaming Experience

USB 2.0 Type-C Right Angle 3A Cable






Right Angle Design



3A Quick Charging



Cotton Braided

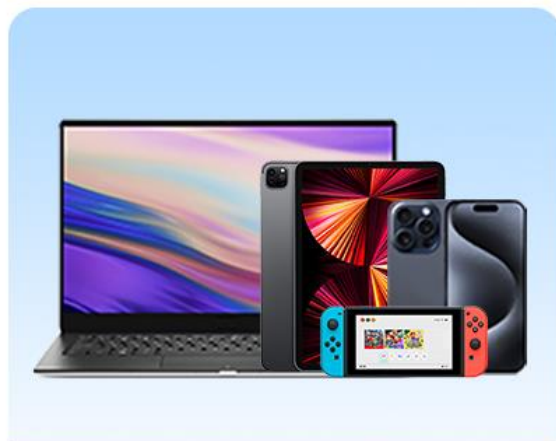

Wide Compatibility

Compatible with iPhone 15 Series

Rapid charging.



30 Minutes Charging Test

iPhone 15 Charged to 59%



iPhone 15 Plus Charged to 57%



iPhone 15 Pro Charged to 57%



iPhone 15 Pro Max Charged to 56%



Note: All data are from Vention Lab.


90-Degree Design

User-friendly design helps you win the MVP.



Long-lasting Performance

No more bending.

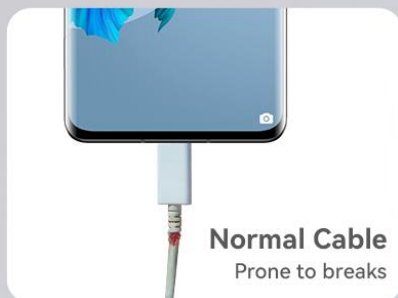


PD60W Quick Charging

Backward compatible with 45W, 30W, 20W, etc.

≈ **2.3** hours 


MacBook Air 13.3-inch

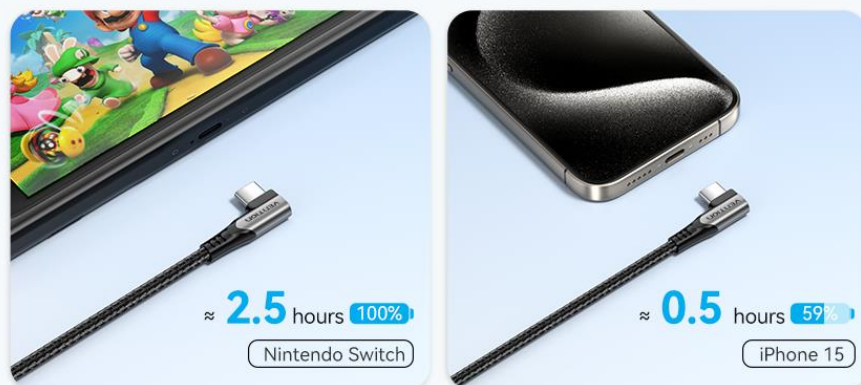

Note: All data are from Vention Lab.

3A Quick Charging

Compatible with quick charging protocols such as PPS, PD, FCP, Qualcomm QC4.0+, etc.

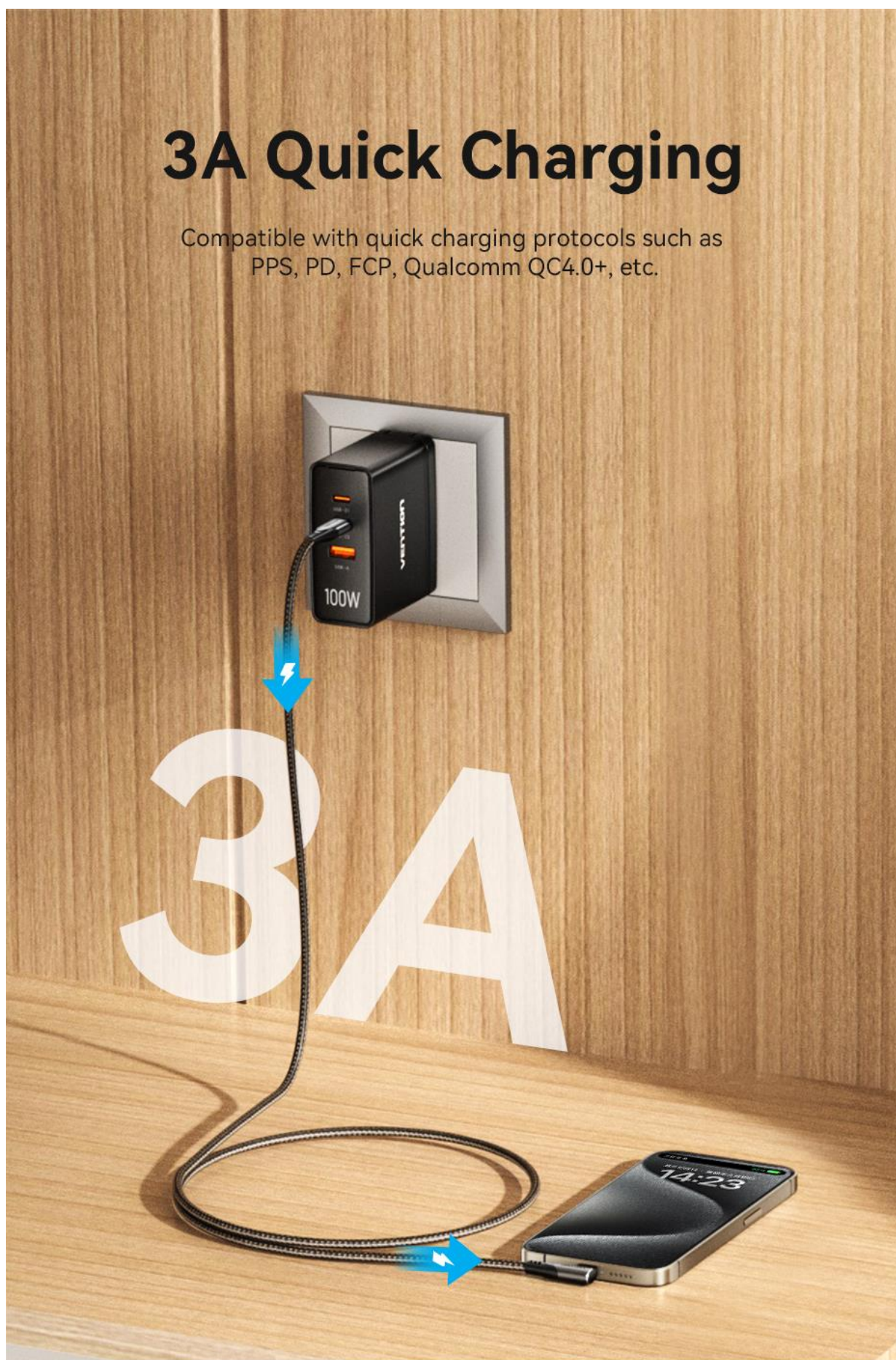

Light-speed Transmission

Charging and data transmission sync.



Note: Do not support video output.


Smart Carplay Connection

Upgrade your travel experience.



Premium Conductor

The robust tinned copper conductor ensures rapid and stable charging.

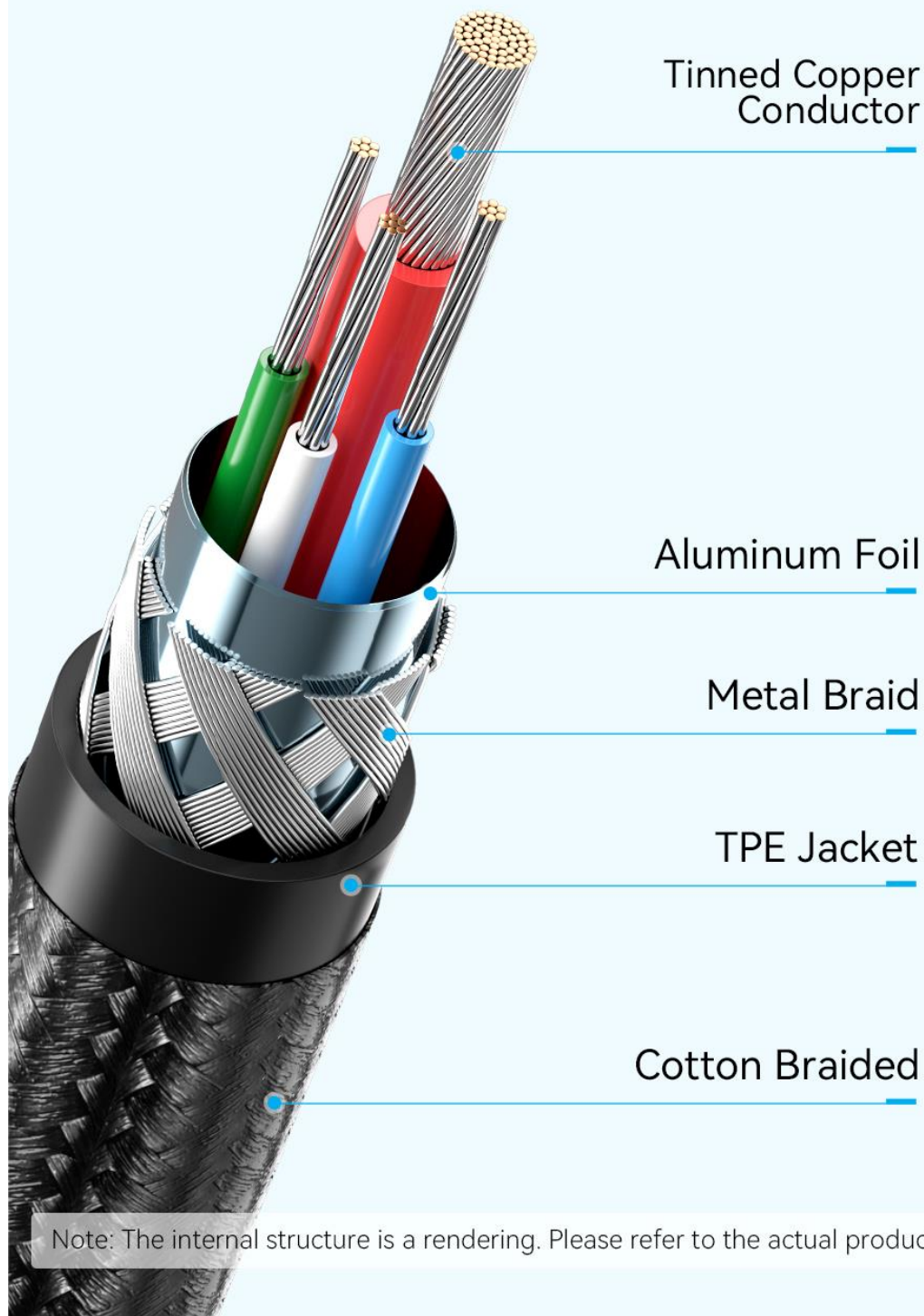

Note: The internal structure is a rendering. Please refer to the actual product.

Universal USB-C Compatibility



Laptop

Apple	MacBook Retina 12", MacBook Air 2018/2019/2020/2022 2023/M1/M2, MacBook Pro 2016/2017/2018/2019/2020 2021/2022/2023/M1/M1 Pro/M1 Max/M2/M3	ASUS	TUF series, Zenbook, ROG Zephyrus ProArt StudioBook, Vivobook, Chromebook
Huawei	MateBook X/X Pro 19/20/21/22/23, MateBook 19/20/21/22 23, MateBook E/E 2019/E 2022/E 2023, MateBook D Series	Dell	XPS 13/15/17, G3/G5/G7/G15/G16, Latitude 7330/7430 9330/9430, Inspiron 16 Plus, Alienware Series
Honor	MagicBook X Series, MagicBook N Series MagicBook View Series, MagicBook Z Series	Lenovo	Legion Y7000/Y7000P/Y9000K, Xiaoxin Pro 14/16 2022 2023, YOGA Pro 14u/16u 2021/2022 ThinkPad X1 Carbon 2021/2022
Xiaomi	Xiaomi Book Pro 14/15 (2021/2022/2023) Xiaomi Book Air 13 2022, Redmi G Gaming Book 2020/2021 2022, Redmi G Pro Gaming Book 2022	Google	PixelBook
HP	Omen Gaming, Pavilion, Victus, Spectre x360, Envy	Razer	Blade 14/15/16/17/18, Blade Stealth
		Microsoft	Surface Laptop 3/4/5/Studio/Go 2/3

Phone

Apple	iPhone 15/15 Plus/15 Pro/15 Pro Max	Black Shark	Black Shark 2/3/4/4 Pro/4S Pro/5/5 RS/5 Pro
Samsung	Z Fold3/4/5, Z Flip3/4/5, S22/22+/22 Ultra, S23/23+ S23 Ultra, Note 20/20 Ultra	OnePlus	8/8 Pro/9/9R/9 Pro/10 Pro/11
Huawei	Mate 40/40 Pro, Mate 50/50 Pro, Mate 60/60 Pro 60 Pro+/60 RS, Mate Xs 2/X3/X5, P40/P40 Pro/P50 P50 Pocket/P60/P60 Pro/P60 Art	Nubia	Red Magic 8 Pro/8S Pro/8S Pro+, Legion Phone Z50 50 Ultra/50S Pro
Lenovo	Legion Y70/Y90	ASUS	ROG 5/5e/5e Pro/6/6 Pro/7/7 Pro

Tablet

Apple	iPad Pro 2018/2020/2021/2022/M1/M2 iPad Air (4th generation) or newer	Microsoft	Surface Pro 7/7+/8/8, Surface Go/Go 2/Go 3
Huawei	MatePad Pro 13.2"	Lenovo	Xiaoxin Pad 2021/2022, Xiaoxin Pad Pro 2021/2022 Yoga Pad Pro, Legion Y700/Y900

Others

Others	Switch Game Console, ower Bank, Bluetooth Earbuds, Smart Watch
--------	--

Specifications

Brand	Vention
Name	USB 2.0 Type-C Cable
Model	TRA
Color	Black
Interface	USB-C
Data Transfer Rate	480Mbps
Electroplating Process	Nickel-plated
Conductor	Tinned Copper
Shell	Aluminum Alloy
Jacket	TPE + Cotton Braided
Length	0.5/1/1.5/2 m
Power Supply	3A
Warranty	1 Year
Packing	PE Bag



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only.



USB 2.0 Type-C Cable

Technical Features		
Color	Gray	
Interface	USB-C	
Connector Process	Nickel-Plated	
Transmission Direction	USB-C - USB-C	
Jacket	PVC + Nylon braided	
Material	Aluminum alloy	
OD	3.3mm	
Data transfer rates	480Mbps	
Output current	3A Max	
Rated power	60W Max	
Length	Art.No.	EAN Code
0.5m	TRAHD	6922794781597
1m	TRAHF	6922794781603
1.5m	TRAHG	6922794781610
2m	TRAHH	6922794781627
Package Contents		
USB 2.0 Type-C Cable x 1		
Packaging Information		
Packing Dimension	22*15cm	
Packing Weight	0.02kg(0.5m)/ 0.03kg(1m)/0.047kg(1.5m)/0.058kg(2m)	
Carton Dimension	48*29*31cm	
Carton Qty	300pcs(0.5m)/ 200pcs(1m)/180pcs(1.5m)/160pcs(2m)	
Carton Weight	7kg(0.5m)/ 7kg(1m)/9.46kg(1.5m)/10.28kg(2m)	

