

## Dławiki PG IP67 i metryczne MG IP67

PG cable glands IP67 and MG metric cable glands IP67


IP67

### Dławiki PG IP67 / PG cable glands IP67

| Numer katalogowy | Typ Type | Ø montażu<br>Ø assembly | D1   | D2   | B1   | L1   | L2   | L3   | Ø przewodu<br>Wire diameter | Klucz / Spanner | Norma Norm | Opakowanie : sztuk<br>Quantity in package |
|------------------|----------|-------------------------|------|------|------|------|------|------|-----------------------------|-----------------|------------|-------------------------------------------|
| Catalogue number | [-]      | [mm]                    | [mm] | [mm] | [mm] | [mm] | [mm] | [mm] | [mm]                        | [mm]            | [-]        | [-]                                       |
| D.3070           | PG-7     | 12,5                    | 11,7 | 8,5  | 6    | 8    | 14,5 | 14,3 | 3,5 - 6,0                   | 16 / 18         | DIN 40430  | 50                                        |
| D.3071           | PG-9     | 15,2                    | 14   | 11   | 8,5  | 8,1  | 16,5 | 15,3 | 6,0 - 8,0                   | 18 / 22         | DIN 40430  | 50                                        |
| D.3072           | PG-11    | 18,3                    | 17,6 | 13,2 | 9,6  | 8,5  | 16,5 | 16,8 | 8,0 - 10,0                  | 22 / 24         | DIN 40430  | 50                                        |
| D.3073           | PG-13,5  | 19,5                    | 18,5 | 15,2 | 12,2 | 8,6  | 17,5 | 16,8 | 10,0 - 12,0                 | 24 / 26         | DIN 40430  | 50                                        |
| D.3074           | PG-16    | 22,5                    | 21,2 | 17,2 | 14,5 | 10   | 17,5 | 18,1 | 12,0 - 14,0                 | 26 / 30         | DIN 40430  | 50                                        |
| D.3075           | PG-21    | 28,2                    | 27,1 | 22   | 18,5 | 11   | 19,5 | 23,5 | 14,0 - 18,0                 | 32 / 36         | DIN 40430  | 50                                        |
| D.3076           | PG-29    | 37,2                    | 35,9 | 30,6 | 25,5 | 11,5 | 23   | 25,5 | 18,0 - 25,0                 | 42 / 45         | DIN 40430  | 10                                        |
| D.3077           | PG-36    | 47,2                    | 45,8 | 38,9 | 33,3 | 14,4 | 25   | 29,5 | 25,0 - 32,0                 | 51 / 58         | DIN 40430  | 10                                        |
| D.3078           | PG-42    | 53,9                    | 52,2 | 46,5 | 39,6 | 15,2 | 26,5 | 30,5 | 32,0 - 38,0                 | 60 / 64         | DIN 40430  | 10                                        |
| D.3079           | PG-48    | 59,3                    | 58,2 | 49,0 | 45,1 | 15,2 | 27,0 | 30,0 | 38,0 - 44,0                 | 64 / 68         | DIN 40430  | 10                                        |


### Dławiki metryczne MG IP67 / MG metric cable glands IP67

| Numer katalogowy | Typ Type | Ø montażu<br>Ø assembly | D1   | D2   | B1   | L1   | L2   | L3   | Ø przewodu<br>Wire diameter | Klucz / Spanner | Norma Norm  | Opakowanie : sztuk<br>Quantity in package |
|------------------|----------|-------------------------|------|------|------|------|------|------|-----------------------------|-----------------|-------------|-------------------------------------------|
| Catalogue number | [-]      | [mm]                    | [mm] | [mm] | [mm] | [mm] | [mm] | [mm] | [mm]                        | [mm]            | [-]         | [-]                                       |
| D.3088           | M12      | 12                      | 10   | 8    | 6    | 7,5  | 14,7 | 15,5 | 3,0 - 6,5                   | 16 / 18         | PN-EN 50262 | 25                                        |
| D.3089           | M16      | 16                      | 14,3 | 10,7 | 8    | 7,5  | 14,7 | 15,3 | 6,5 - 8,0                   | 19 / 22         | PN-EN 50262 | 50                                        |
| D.3080           | M20      | 20                      | 18,5 | 14,7 | 12   | 9,5  | 17   | 18,2 | 8,0 - 12,0                  | 24 / 27         | PN-EN 50262 | 25                                        |
| D.3081           | M25      | 25                      | 23,3 | 19   | 18   | 10   | 20   | 23,5 | 12,0 - 18,0                 | 32 / 32         | PN-EN 50262 | 25                                        |
| D.3082           | M32      | 32                      | 30,4 | 24   | 25   | 11   | 20   | 21,5 | 18,0 - 24,0                 | 36 / 38         | PN-EN 50262 | 10                                        |
| D.3083           | M40      | 40                      | 38,1 | 33   | 32   | 15   | 17   | 29,5 | 24,0 - 32,0                 | 51 / 50         | PN-EN 50262 | 10                                        |
| D.3090           | M50      | 50                      | 38   | 38   | 40   | 14   | 24   | 32,5 | 32,0 - 38,0                 | 60 / 68         | PN-EN 50262 | 10                                        |
| D.3091           | M63      | 63                      | 61,7 | 54   | 45   | 14   | 35   | 40,5 | 38,0 - 45,0                 | 70 / 76         | PN-EN 50262 | 10                                        |

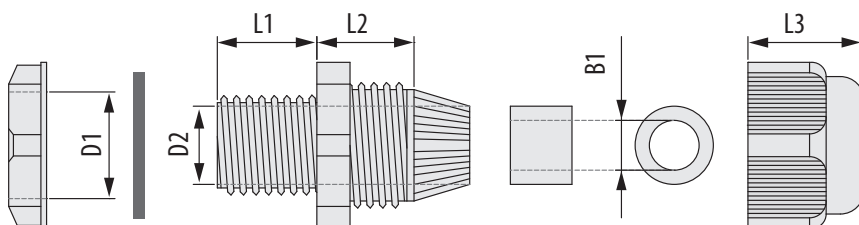

### Dławiki gumowe PG / PG rubber cable glands

| Numer katalogowy | Typ Type | Ø montażu<br>Ø assembly | Norma Norm | Opakowanie: sztuk<br>Quantity in package |
|------------------|----------|-------------------------|------------|------------------------------------------|
| Catalogue number | [-]      | [mm]                    | [-]        | [-]                                      |
| D.3410           | PG-13,5  | 20,5                    | DIN 40430  | 100                                      |
| D.3411           | PG-16    | 22                      | DIN 40430  | 100                                      |
| D.3412           | PG-21    | 29                      | DIN 40430  | 100                                      |
| D.3413           | PG-29    | 37                      | DIN 40430  | 100                                      |

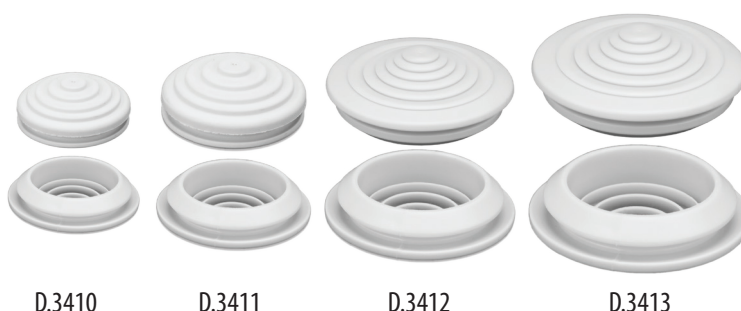

D.3410

D.3411

D.3412

D.3413