



Excellent Scalability

Fulfill your multiple needs



Note: All data are from Vention Lab



RJ45 1000Mbps Interface

No Lag for Online Movie

More stable than Wifi connection



Efficient
office



Smooth
film



High speed
download



No delay
in gaming




1000Mbps

Note: All data are from Vention Lab



USB Port

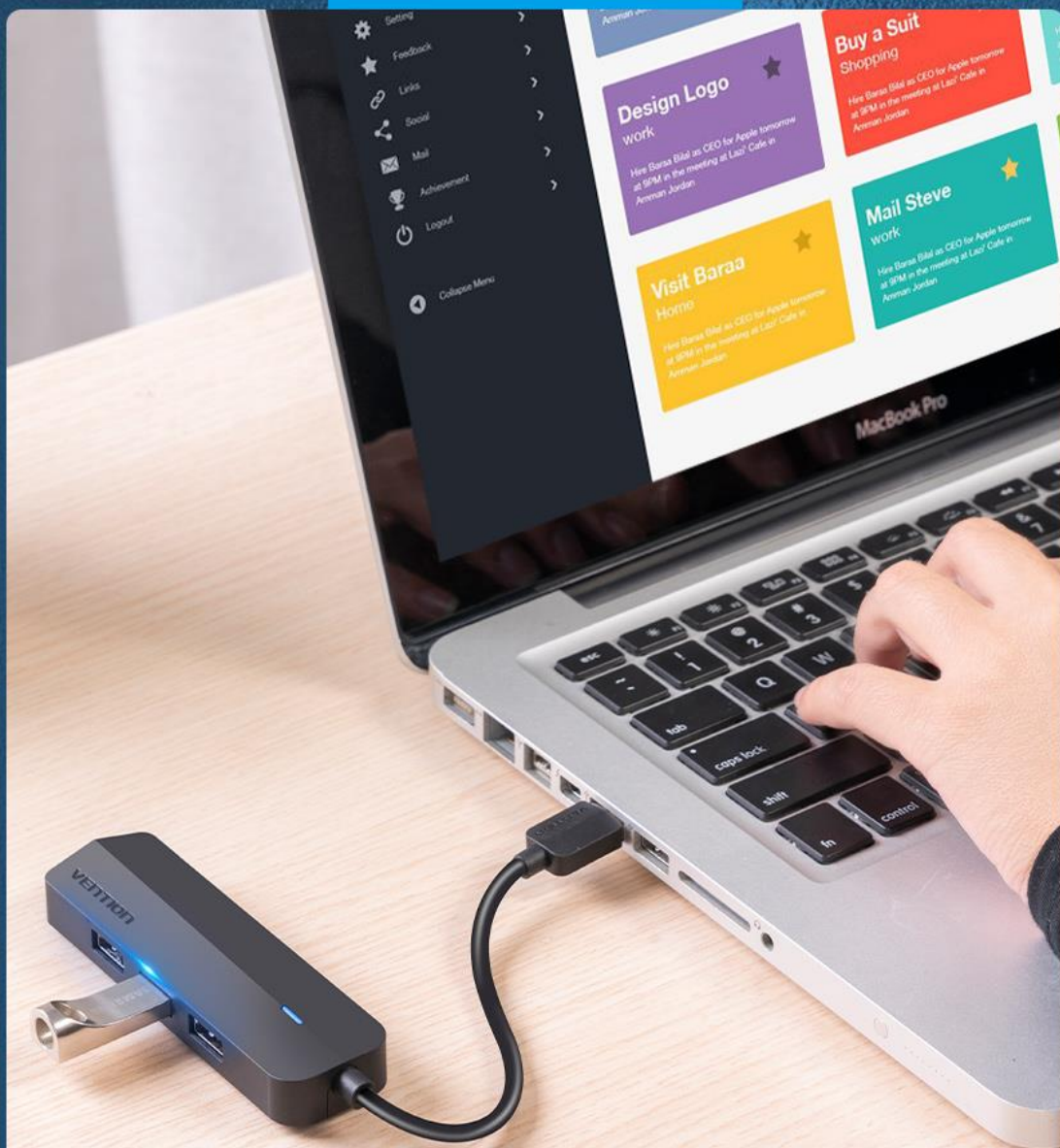

1GB File
within 3 Seconds

5Gbps theoretical speed, photo/large files within reach

Note: All data are from Vention Lab

No Delay for Mouse Connection

Flexible operation for game



Access to **8TB** Hard Disk

By external power supply,
easily drive large capacity hard disk



Note: All data are from Vention Lab

Emergency Charging for Cellphones

Via external power supply, two charging
ports available for power supply





RJ45
1000 Mbps
Ethernet port



USB3.0*3

4 Ports Expansion

Simultaneous connection of 1000M
LAN cable and 3 USB devices

Upgraded **Chips** for Perfect Performance

Realtek network card chip with high speed 3.0 HUB chip
high-speed network and transmission

HUB: VL817
RJ45: RTL8153



Notice: The internal chip/circuit board is a rendering,
please in kind prevail

Universal Compatibility

Compatible with mainstream operating systems



Windows10



Windows8



Windows7



Vista



Windows xp



Mac OS



Linux

Applicable for Computers with USB Ports



Apple



Lenovo



Dell



Asus

Blue Indicator Light

Check operating status




Exquisite Details

01

Anti-interference

Tinned copper wire,
aluminum foil + metal
shield, TPE covering

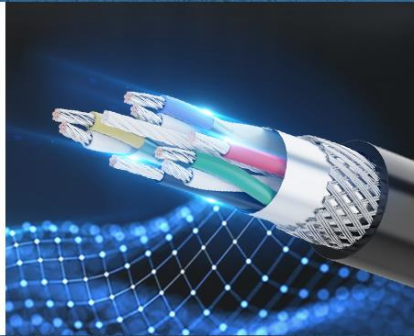

02

ABS shell

High temperature
resistance
Wear-resistance



03

Anti-breakage

Tough TPE material
4.8mm bold wire



04

Portable

Easy to carry around




Enjoy Wired Gigabit Network

Perfect compatibility with your Xiaomi Mi Box 3/s



Product Parameters

Brand: Vention
Name: 3-Port USB 3.0 Hub with Gigabit Ethernet Adapter
Model: CHNBB
Color: Black
Interface: USB 3.0 Male/USB 3.0 Female*3/ USB 2.0 Micro-B Female/RJ45 Female
Interface Technics: Nickel-plated
Transmission Speed: 5Gbps
Network Speed:10/100/1000Mbps
Rated power supply:5V==2A
Conductor: Tinned Copper
Shell: ABS
Chip: VL817(HUB)+RTL8153(RJ45)
Shielding: Aluminum Foil+Metal Braided
Jacket: TPE
AWG: 24+30AWG
OD: 4.8mm
Length: 0.15m
Warranty: 1 Year
Packing: Color Box

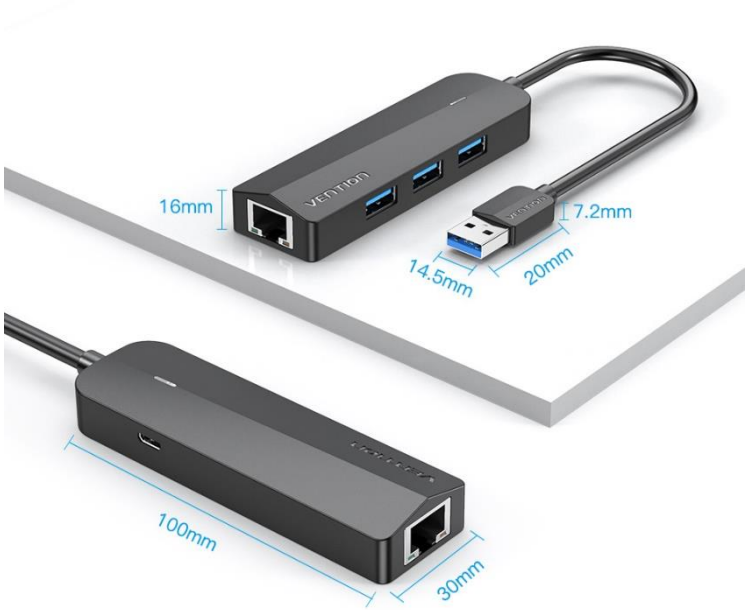

Note:All data are from Vention Lab.
Sizes above are manually measured.There might be slight tolerance



Note: Packing difference exists for different meters or batches
The photo is for reference only



5-in-1 USB 3.0 Hub

Technical Features	
Color	Black
Interface	USB/USB 3.0 x 3/RJ45/Micro-B
Connector Process	Nickel-Plated
Material	ABS
Input power	5V $\overline{=}$ 2A
Data transfer rates	5Gbps (USB 3.0)
Transmission rate	10/100/1000Mbps

Length	Art.No.	EAN Code
0.15m	CHNBB	6922794747289



Package Contents
5-in-1 USB 3.0 Hub x 1

Packaging Information	
Packing Dimension	17.25*9.25*2.75cm
Packing Weight	0.081kg
Carton Dimension	48*29*30cm
Carton Qty	70pcs
Carton Weight	6.67kg