



Premium Speaker Wire

It combines great looks and durability with exceptional sonic performance, making it the ideal speaker wire solution for the serious audiophile.

Sturdy
Brass Plug



Professional Grade

Hi-Fi

Drawing from extensive experience in cable design and countless listening tests over the years, Vention ensures high-quality offerings for its customers.




Graphene PVC Insulation

Graphene PVC is a lower-loss dielectric material and provides more detailed and transparent sound.




Graphene

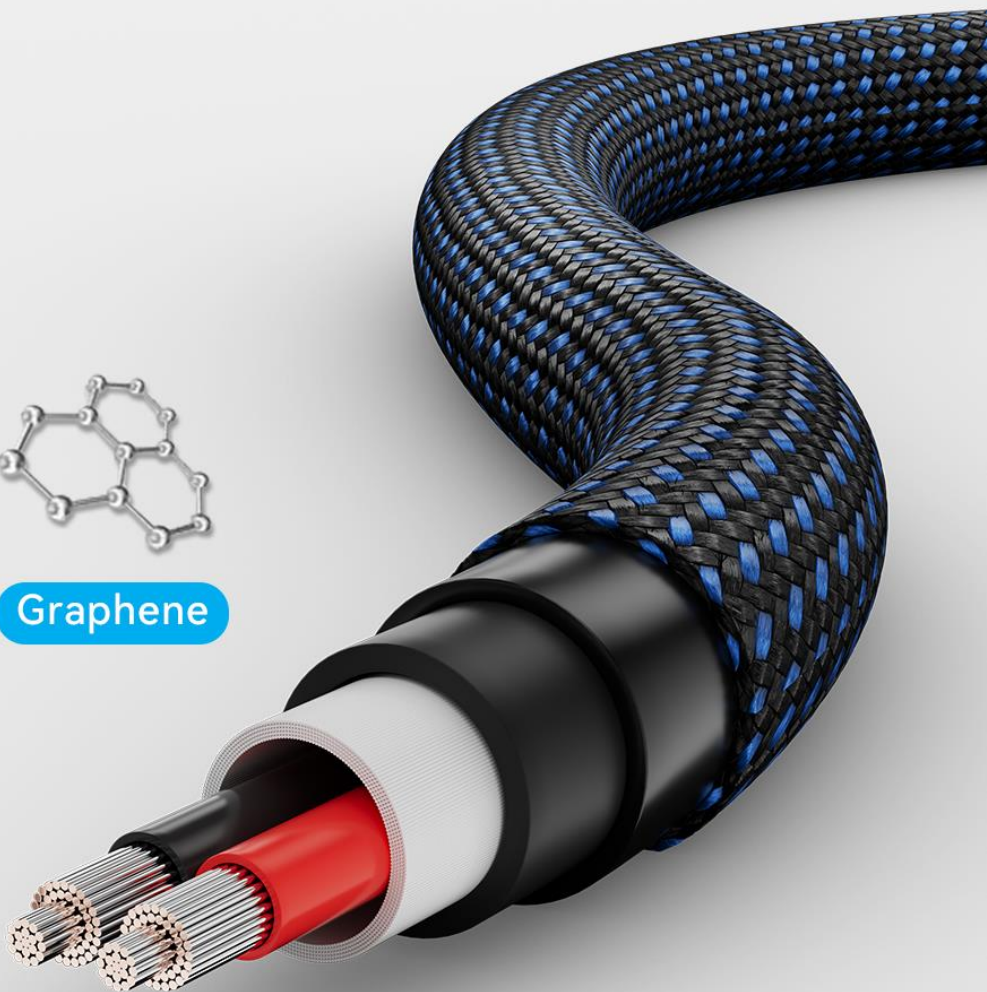

Note: The internal structure is a rendering.
Please refer to the actual product.

Quality Construction

12AWG 4N silver-plated oxygen-free copper conductors and insulation to minimize signal interference and maintain signal integrity.

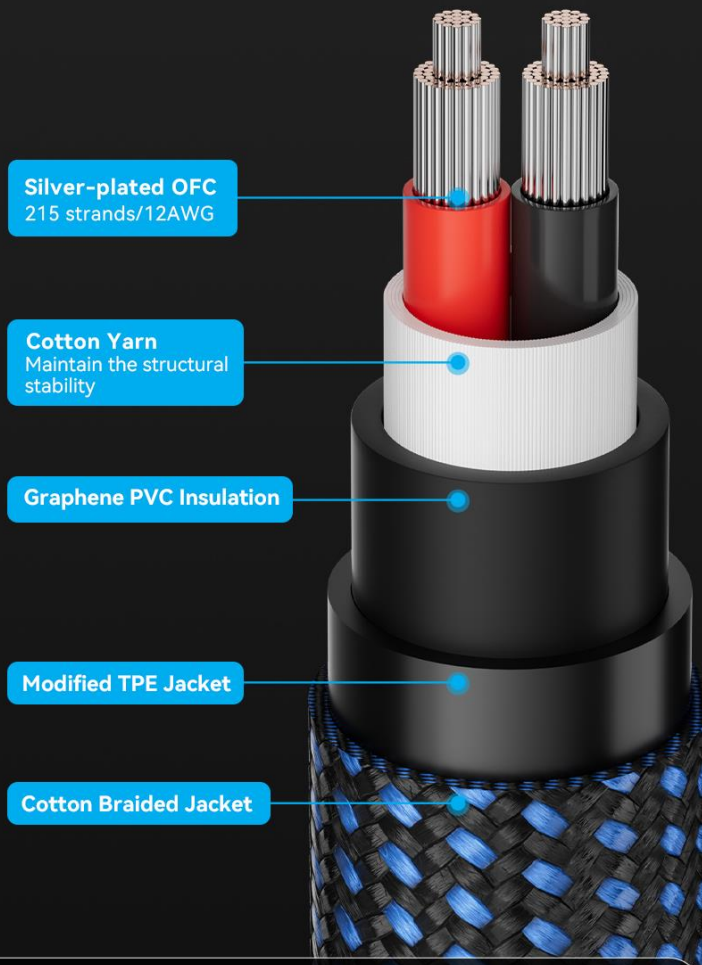

Silver-plated OFC
215 strands/12AWG

Cotton Yarn
Maintain the structural stability

Graphene PVC Insulation

Modified TPE Jacket

Cotton Braided Jacket



Note: All data are from Vention Lab. The internal structure is a rendering; please refer to the actual product.

Long Lasting Durability

Closed Screw Type

Secure connection



24K Gold-Plated Plugs

Corrosion resistant



Soft-Touch & Durable

These wires have been wrapped in modified TPE and braided fabric, giving them a soft-touch to protect your speakers' finish, yet retaining the flexibility of ordinary speaker wire.



Reliable



Flexible



Durable

14mm

Thickened OD

Universal Compatibility

Source



Amplifier



Sound Receiver

Output



Center Speaker



Floor-standing Speaker



Bookshelf Speaker




Pin Plug



Spade Plug

Specifications

Brand	Vention
Name	Dual Banana Plugs to Dual Spade Plugs Speaker Wire (Hi-Fi)
Model	BLC
Color	Blue
Type	Closed screw
Interface	Banana plug/Spade plug
Electroplating process	Gold-Plated
Conductor	4N silver-plated oxygen-free copper
Shell	Brass + Resin
Insulation	Graphene PVC
Jacket	TPE (modified) + Cotton braided
Length	1 m - 10 m
Warranty	1 year
Packaging	Gift box

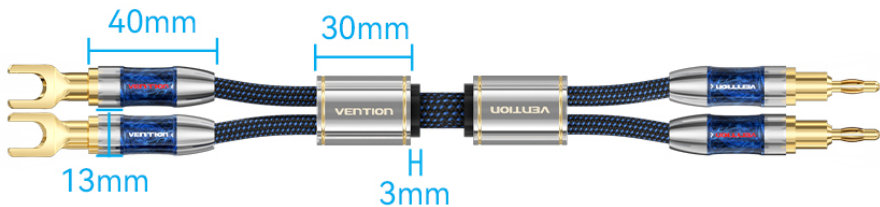

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only.

